

Patch Cables Cat.6a UL

PiMF S/FTP



SPECIFICATION:

Frequency: 500 MHz
 Operating Temperature: -10°C to 75°C
 PoE voltage (Max.): 57 V




MATERIAL:

Material (Sheath): PVC (UL-CMX)
 Material (Shield): copper alloy, nickel plated
 Material (Contact Area): copper alloy, 3 μ" gold plating
 Connector: UL1863
 Cable Diameter (Max.): 5.8 mm



HANDLING:

Packaging: Bag, single-packed

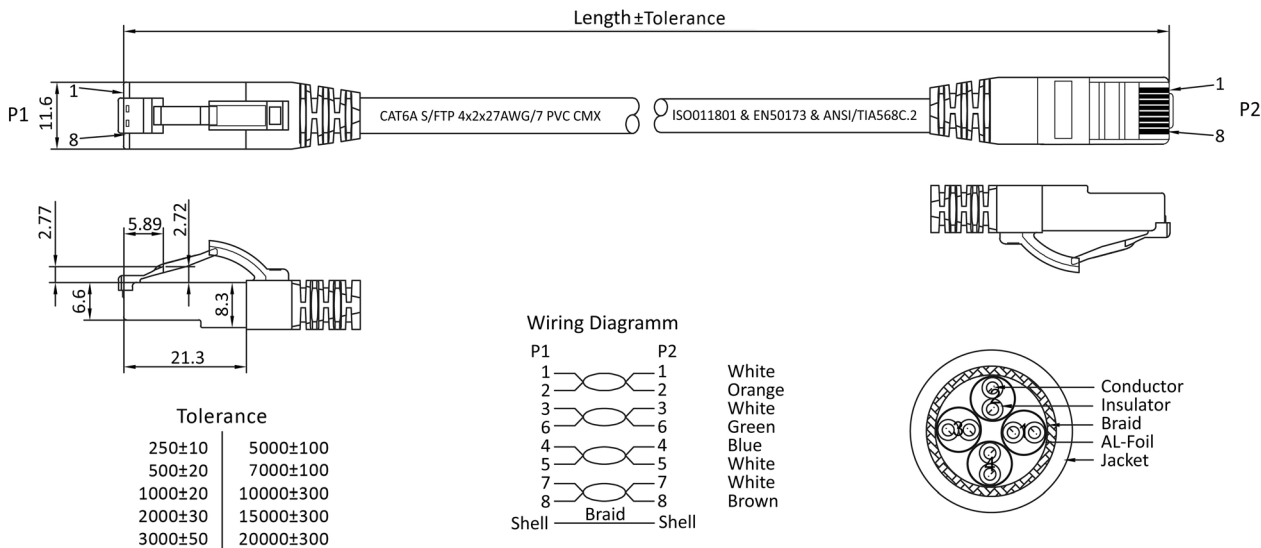

Order Information

Identifier:	Length:	Colour:	Version:
S6TP	#	GR	U
Patch Cord S/FTP Cat.6a shielded	0,25: 0.25 m	grey	UL listed
	0,5: 0.5 m		
	1: 1.0 m		
	2: 2.0 m		
	3: 3.0 m		
	5: 5.0 m		
	7: 7.0 m		
	10: 10.0 m		
	15: 15.0 m		
	20: 20.0 m		