

Pin Headers
Pitch 2.0 mm, straight

Double row PBT, length 8.8 mm



SPECIFICATION:

Operating Current (Nom.): 2 A
 Operating Temperature: -40°C to 105°C
 Insulation Resistance (Min.): 1000 MΩ
 Contact Resistance (Max.): 20 mΩ
 Dielectric Strength: 500 Vac (1 min)

MATERIAL:




Material (Insulation): PBT
 Flammability Class: UL 94 V-0
 Material (Contact Area): copper alloy, gold plated

HANDLING:



Processing: wave soldering
 Packaging: bulk

TOLERANCE:

.X: ± 0.25
 .XX: ± 0.20

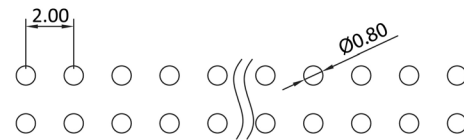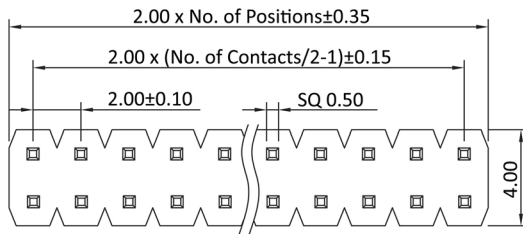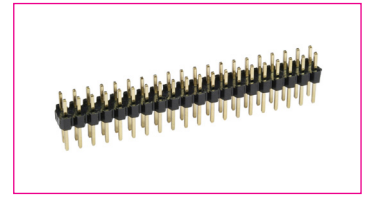

Recommended PCB Layout
(PCB Tolerance ±0.05)

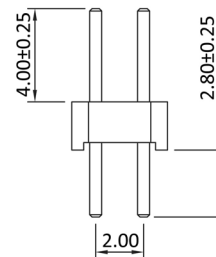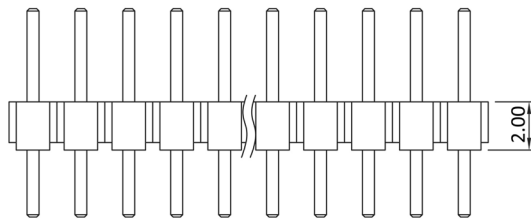

Order Information

Identifier:	No. of Contacts:	Version:	Special:	Pitch:
SL	#	G	2	R2
Pin header pitch 2.0 mm	2: 2 x 2 3: 2 x 3 4: 2 x 4 : 40: 2 x 40	straight	double row	pitch 2.0 mm