

# Pin Headers Pitch 2.54 mm SMT

Double row, SMT, height 9.3 mm




### SPECIFICATION:

Operating Current (Nom.): 3 A  
 Operating Temperature: -40°C to 105°C  
 Insulation Resistance (Min.): 1000 MΩ  
 Contact Resistance (Max.): 20 mΩ  
 Dielectric Strength: 1,000 Vac



### MATERIAL:

Material (Terminal): copper alloy  
 Material (Insulation): nylon 6T  
 Flammability Class: UL 94 V-0  
 Material (Contact Area): copper alloy, gold plated

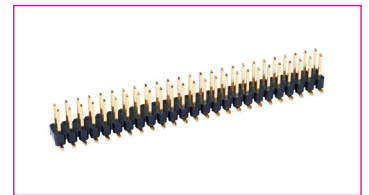


### HANDLING:

Processing: reflow soldering

### TOLERANCE:

.X: ± 0.25  
 .XX: ± 0.20

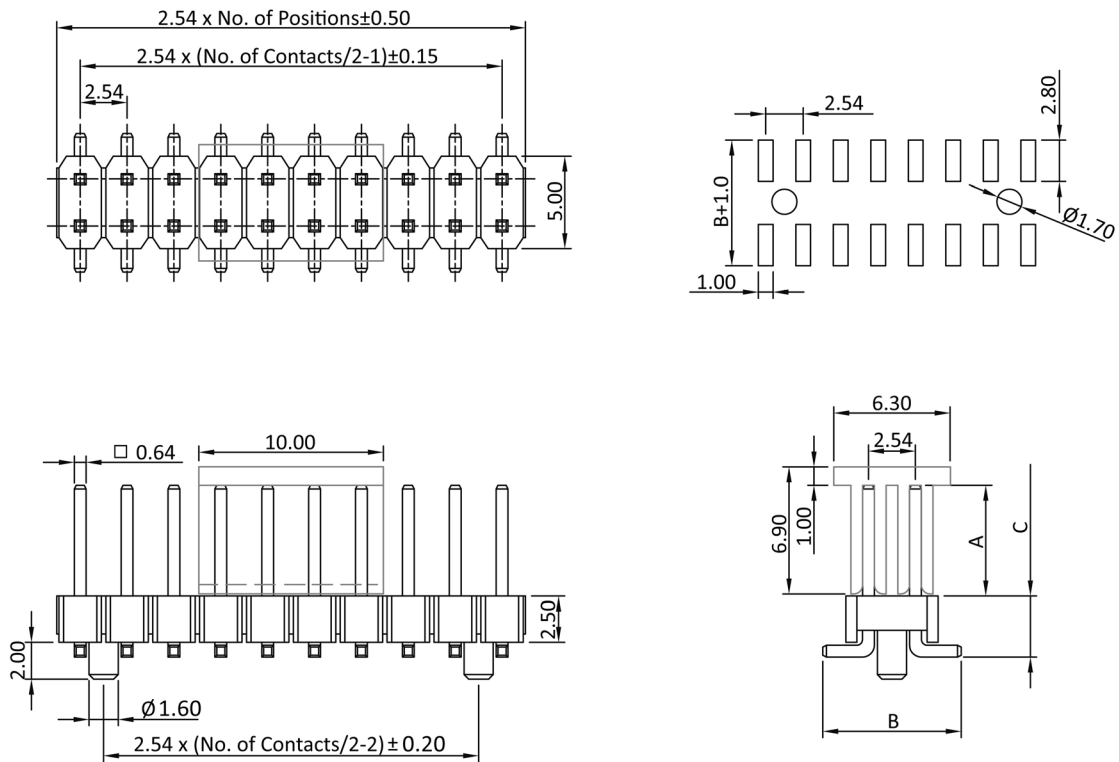

### Order Information

Identifier:	No. of Contacts:	Contact Plating:	Packing:	Version:	Length:
<b>SMZ</b>	<b>#</b>	<b>G</b>	<b>#</b>	<b>#</b>	<b>#</b>
SMT Pin header pitch 2.54 mm double row straight	4: 2 x 2 6: 2 x 3 8: 2 x 4 : 80: 2 x 40	gold plated	B: bulk T: tube * R: tape & reel *	O: w/o cap + peg * C: with Cap * P: with Peg T: with Cap + Peg	D: A=6.0 B=7.5 C=3.3 * X: Special dimensions also available

\* = Standard