

USB Cables USB 3.2

Connection cable C male on C female



SPECIFICATION:

Insulation Resistance (Min.): 10 MΩ
 Contact Resistance (Max.): 3 Ω
 Transmission Rate: 20 Gbps




MATERIAL:

Colour: black
 Diameter: 4.5 mm
 Material (Sheath): TPE (thermoplastic elastomer)
 Material (Housing): PVC
 Material (Insulation): PBT
 Material (Contact): gold plated
 Material (Shell): nickel plated
 Cable: [32AWG TCx1P+D 32AWG TC+D+AL/MY] x 4C+1P x 32AWG TC + 4C x 32AWG TC + 2C x 22AWG TC)+F+AL+Braid



HANDLING:

Packaging: Bag, single-packed
 Note: 100 % open short & miss wire test

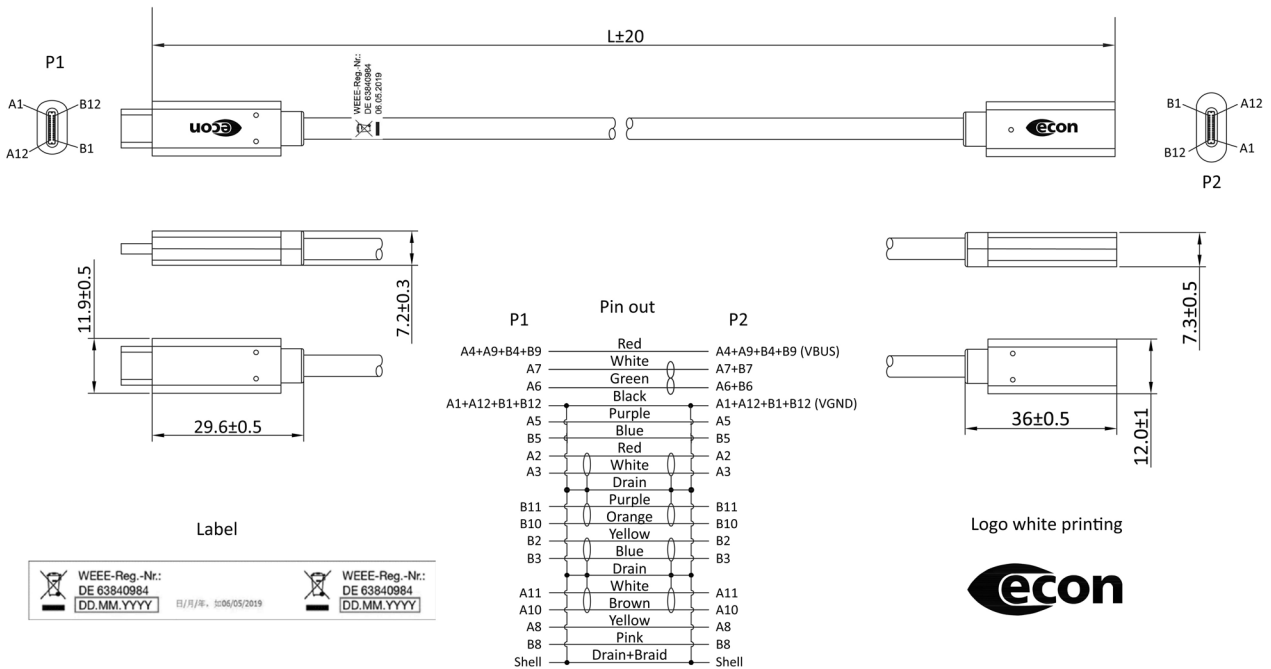

Order Information

Identifier:	Length:	Colour:
U32CCF	1	SW
USB 3.2 extension cable USB C male on USB C female	1.0 m	black