

# USB Connectors USB 2.0 Sockets Type B


SMT, vertical



### SPECIFICATION:

Operating Voltage (Max.):	250 V
Operating Current (Nom.):	1.5 A
Operating Temperature:	-55°C to 85°C
Insulation Resistance (Min.):	1000 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	750 Vac
Insertion Force (Max.):	35 N
Extraction Force:	10 N

SMT

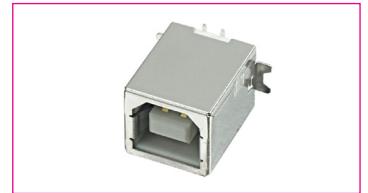

### MATERIAL:


Material (Terminal):	phosphor bronze, tin plated
Material (Housing):	brass, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	nylon PA 9T
Material (Contact Area):	phosphor bronze, gold plated

### HANDLING:

Packaging:	tray
------------	------

### TOLERANCE:

.X:	± 0.25
.XX:	± 0.13

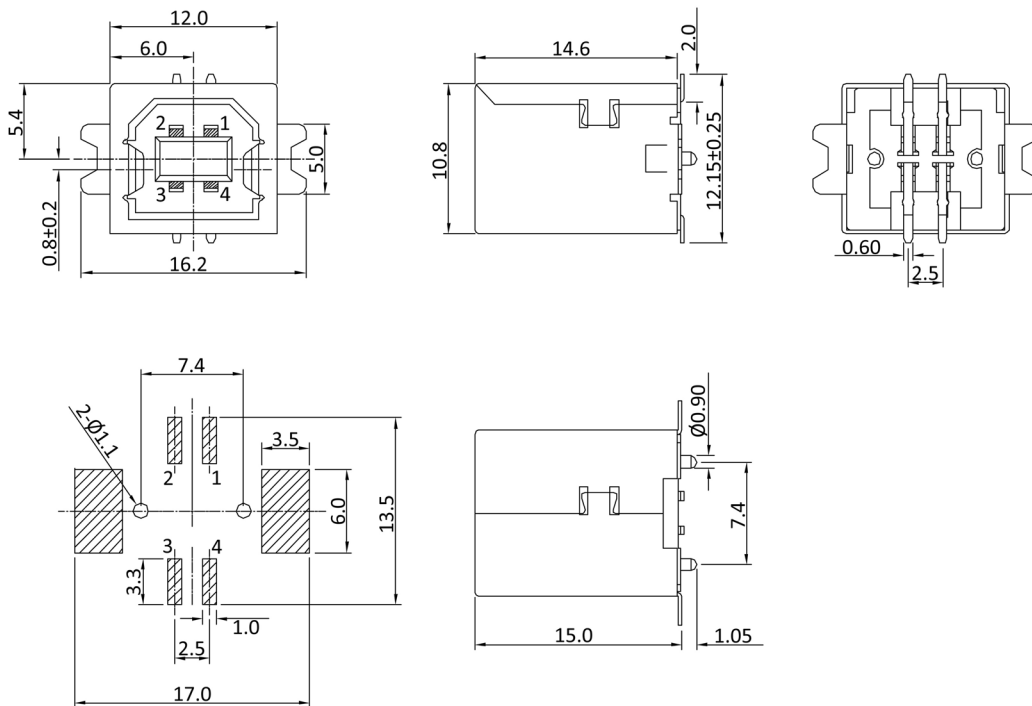

### Order Information

Identifier:

**UBU1BSMDH**

SMT Socket type B vertical

Version:

#

empty: w/o pp pad

C: with pp pad