

# DIN 41651 Flat Cable Connector System Box Headers with Locking

Pitch 2.54 mm, IDC, long latches



### SPECIFICATION:

Operating Current (Nom.): 3 A  
 Operating Temperature: -55°C to 105°C  
 Insulation Resistance (Min.): 5000 MΩ  
 Contact Resistance (Max.): 30 mΩ  
 Dielectric Strength: 1,000 Vac

### MATERIAL:


 



Material (Housing): PBT  
 Flammability Class: UL 94 V-0  
 Material (Contact Area): copper alloy, gold plated

### HANDLING:

Packaging: tray

### TOLERANCE:

.X: ± 0.30  
 .XX: ± 0.20

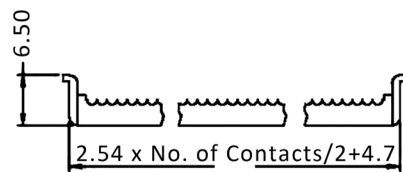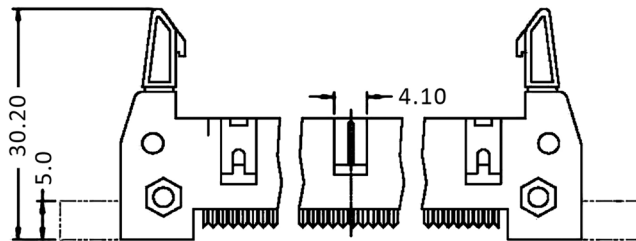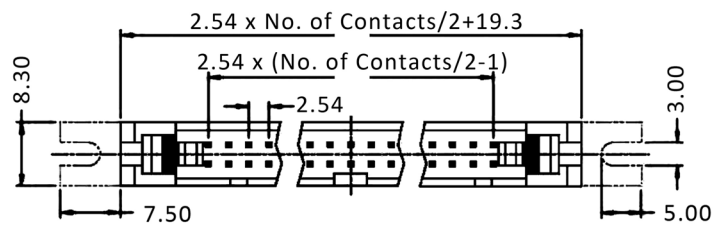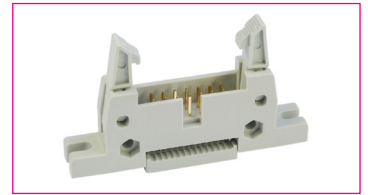

### Order Information

Identifier:	No. of Contacts:	Version:	Locking:
<b>WS</b>	<b>#</b>	<b>SK</b>	<b>VL</b>
Box header with flange pitch 2.54 mm	10: 2 x 5	IDC	long latches
	14: 2 x 7		
	16: 2 x 8		
	20: 2 x 10		
	24: 2 x 12		
	26: 2 x 13		
	30: 2 x 15		
	34: 2 x 17		
	40: 2 x 20		
	50: 2 x 25		
	60: 2 x 30		