


Quartz Crystal


SMD-version

part no.	12.60157
model	KX – 7T
frequency	25,0 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±30 ppm
temperature tolerance -40° ~ +85°C	±30 ppm
load capacitance C_L	18 pF
series resonance R1 max.	40 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C_0 max.	3,5 pF
drive level	100 μ W typ., 200 μ W max.
contents of reel	1000 pcs.


Dimensions (mm):

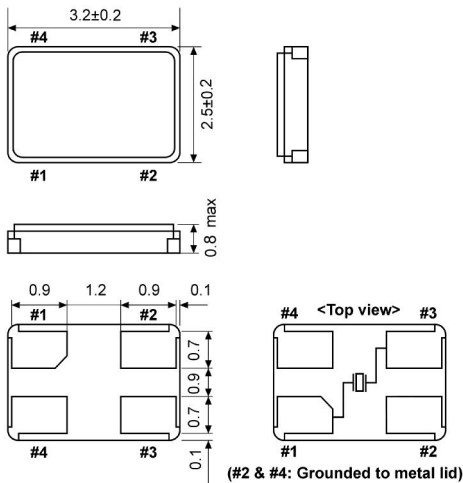

Reflow soldering condition:

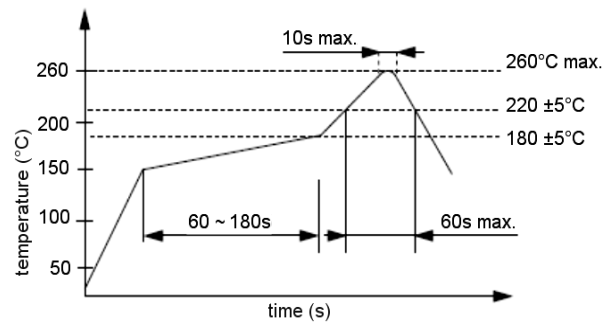

Suggested soldering pad:

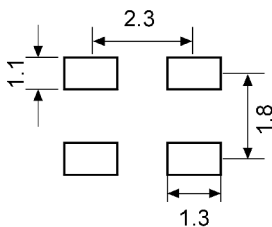

Tape specification:

