


## Quartz Crystal


SMD-version

model	KX - 7
frequency	16,0 MHz
mode	fundamental
operating temperature	-20° ~ + 70°C
frequency tolerance at +25°C	± 30 ppm
temperature tolerance -20° ~ + 70°C	± 50 ppm
load capacitance $C_L$	12 pF
series resonance $R_1$ max.	100 Ohm
aging ( first year )	± 2 ppm
shunt capacitance $C_O$ max.	5,0 pF
drive level in mW max.	0,05
RoHS	according to RoHS 2011/65/EU
contents of reel	1000 pcs.
part no.	12.88602


### Dimensions (mm):

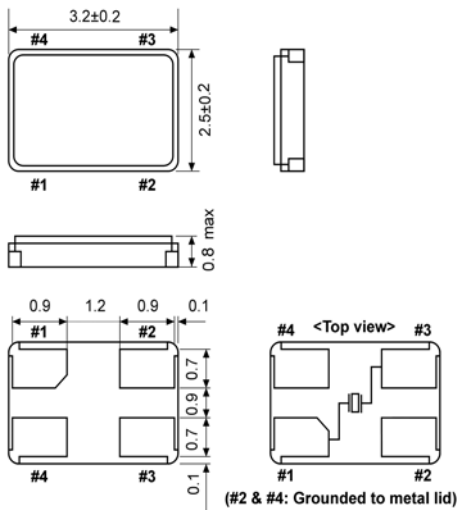

### Suggested soldering pad:

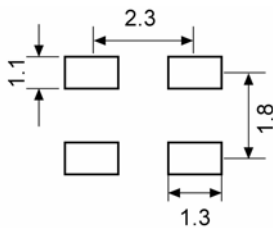

### Reflow soldering condition:

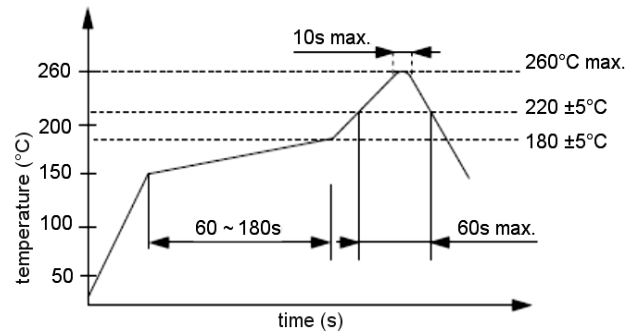

### Tape specification:

