




Item (Detail view)


4-conductor double deck terminal block; Through/through terminal block; L/L; without marker carrier; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; Push-in CAGE CLAMP®

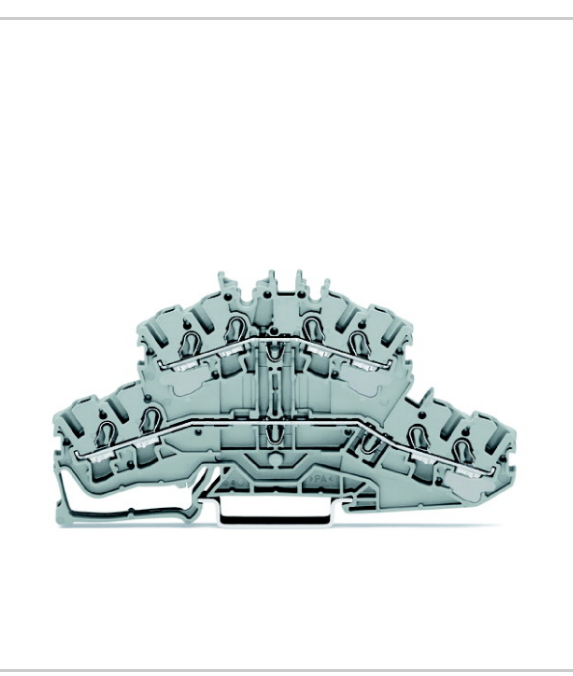

Item no.	2002-2401	GTN / EAN	450062144860
Content	1 piece	Order unit	piece
Order quantity	50 piece	Increase in order quantity	(50, 100, 150, 200, ...)
Customer item no.		Customs Tariff no.	85369010000
Customs duty for the country of origin	CN	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS Compliant

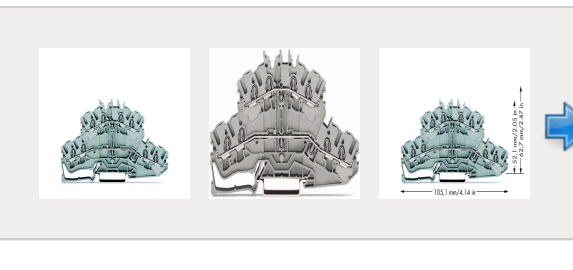

Article details Approvals Downloads/Certificates Accessories

Description 4-conductor double deck terminal block; Through/through terminal block; L/L; without marker carrier; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; Push-in CAGE CLAMP®

Remarks

Item properties

Miscellaneous

Name	Value	Unit
Connection technology	Push-in CAGE CLAMP®	
Number of connection points (connection type)	4	
Actuation type	Push-in	
Connectable conductor materials	Copper	
Nominal cross section	2.5 mm ²	
Solid conductor	0.25 ... 4 mm ² / 22 ... 12 AWG	
Solid conductor, push-in termination	0.75 ... 4 mm ² / 18 ... 12 AWG	
Fine-stranded conductor	0.25 ... 4 mm ² / 22 ... 12 AWG	
Fine-stranded conductor with female, push-in termination, f	0.75 mm ² / 18 AWG	
Strip length	10 ... 12 mm / 0.39 ... 0.47 inch	
Number of connection points (connection type 2)	4	
Total number of connection points	8	
Total number of potentials	2	
Number of levels	2	
Type of wiring	Front-entry wiring	
Width	52 mm / 2.05 in	
Height from upper edge of DIN-35 rail	52.1 mm / 2.051 in	
Depth	105.1 mm / 4.138 in	
Design	horizontal	
Type of mounting	Center rail 35 x 15	
Potential marking	L/L	
Marking level	Centerside marking	
Color	gray	
Insulating material	Polyamide 66 (PA 66)	
Fire load [MJ]	0.291	MJ
Weight [g]	15.750	g
Packaging type	BOX	
[mm]	5.2	mm
Product Family	TOPJOB® S	
Main product function	Multilevel terminal blocks	
Product type	Through rail mount term. blocks	

Upwards