




Item (Detail view)

WMB Inline; for Weidmüller terminal blocks; plain; 1200 WMB markers on roll

Item no.	2009-015	GTN / EAN	4500621059662
Content	1 piece	Order unit	piece
Order quantity	1 piece	Increase in order quantity	(1, 2, 3, 4, ...)
Customer item no.		Customs Tariff no.	4911900000
Customs duty for the country of origin	DE	Available	11/2014
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS Compliant

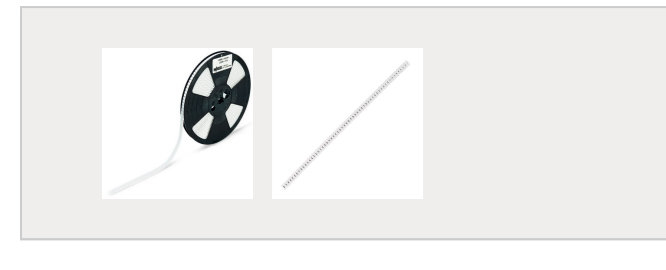

Article details Approvals Downloads/Certificates

Description		WMB Inline; for Weidmüller terminal blocks; plain; 1200 WMB markers on roll																																														
Remarks																																																
Item properties		<table border="1"> <thead> <tr> <th colspan="3">Miscellaneous</th> </tr> <tr> <th>Name</th> <th>Value</th> <th>Unit</th> </tr> </thead> <tbody> <tr> <td>Color</td> <td>white</td> <td></td> </tr> <tr> <td>Marking</td> <td>plain</td> <td></td> </tr> <tr> <td>Marker width [mm]</td> <td>5</td> <td>mm</td> </tr> <tr> <td>Marker width (max.) [mm]</td> <td>5.2</td> <td>mm</td> </tr> <tr> <td>Fine load [MJ]</td> <td>2.34</td> <td>MJ</td> </tr> <tr> <td>Marking device</td> <td>smarPRINTER (Thermal Transfer Printer)</td> <td></td> </tr> <tr> <td>Weight [g]</td> <td>76.53</td> <td>g</td> </tr> <tr> <td>Marker/Strip width</td> <td>5 ... 5.2 mm</td> <td></td> </tr> <tr> <td>Packaging type</td> <td>Beutel</td> <td></td> </tr> <tr> <td>Product Family</td> <td>WMB Inline markers</td> <td></td> </tr> <tr> <td>Main product function</td> <td>Marker</td> <td></td> </tr> <tr> <td>Product type</td> <td>Terminal block marking</td> <td></td> </tr> <tr> <td>Marking available</td> <td>yes</td> <td></td> </tr> </tbody> </table>		Miscellaneous			Name	Value	Unit	Color	white		Marking	plain		Marker width [mm]	5	mm	Marker width (max.) [mm]	5.2	mm	Fine load [MJ]	2.34	MJ	Marking device	smarPRINTER (Thermal Transfer Printer)		Weight [g]	76.53	g	Marker/Strip width	5 ... 5.2 mm		Packaging type	Beutel		Product Family	WMB Inline markers		Main product function	Marker		Product type	Terminal block marking		Marking available	yes	
Miscellaneous																																																
Name	Value	Unit																																														
Color	white																																															
Marking	plain																																															
Marker width [mm]	5	mm																																														
Marker width (max.) [mm]	5.2	mm																																														
Fine load [MJ]	2.34	MJ																																														
Marking device	smarPRINTER (Thermal Transfer Printer)																																															
Weight [g]	76.53	g																																														
Marker/Strip width	5 ... 5.2 mm																																															
Packaging type	Beutel																																															
Product Family	WMB Inline markers																																															
Main product function	Marker																																															
Product type	Terminal block marking																																															
Marking available	yes																																															

Upwards

Item