


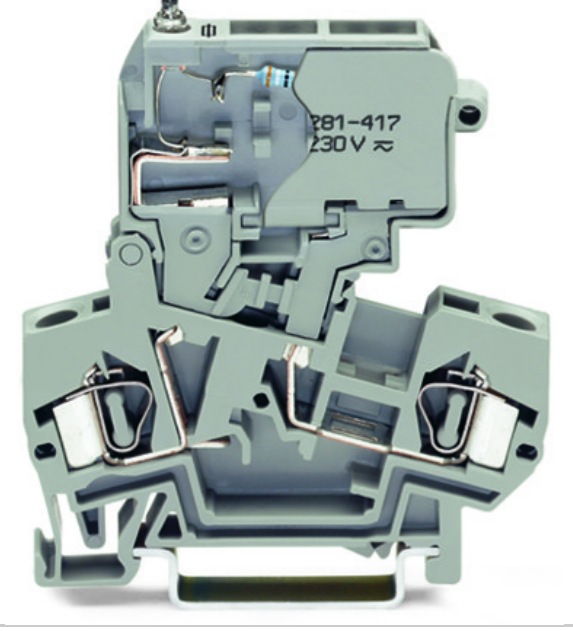

Item (Detail view)


Fuse disconnect terminal block with pivoting fuse holder; for 5 x 20 mm miniature metric fuse; 120 V; with blown fuse indication by neon lamp



Item no.	291-611/281-418	GTN / EAN	4045454871444
Content	1 piece	Order unit	piece
Order quantity	50 piece	Increase in order quantity	(50, 100, 150, 200, ...)
Customer item no.		Customs Tariff no.	85369095990
Customs duty for the country of origin	CN	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS Compliant

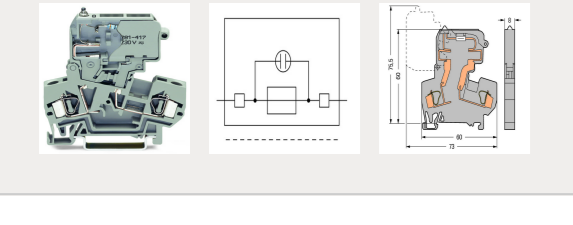

Article details Approvals Downloads/Certificates Accessories

Description Fuse disconnect terminal block with pivoting fuse holder; for 5 x 20 mm miniature metric fuse; 120 V; with blown fuse indication by neon lamp

Remarks **Safety information 1:** Electrical ratings are given by the fuse and blown fuse indication.

Item properties

Miscellaneous		
Name	Value	Unit
Safety information 2	Leakage current in case of blown fuse: Neon lamp < 0.4mA	
Connection technology	CAGE CLAMP®	
Actuation type	Operating tool	
Connectable conductor materials	Copper	
Solid conductor	0.08 ... 4 mm² / 28 ... 12 AWG	
Fine-stranded conductor	0.08 ... 4 mm² / 28 ... 12 AWG	
Strip length	9 ... 10 mm / 0.35 ... 0.39 inch	
Total number of connection points	2	
Total number of potentials	2	
Number of levels	1	
Type of wiring	Front-entry wiring	
Width	8 mm / 0.315 in	
Height from upper-edge of DIN-35 rail	60 mm / 2.362 in	
Depth	60 mm / 2.362 in	
Design	angled	
Type of mounting	Carrier rail 35 x 15	
Marking level	Center marking	
Color	gray	
Insulating material	Polyamide 66 (PA 66)	
Fire load [MJ]	0.335	MJ
Weight [g]	17.538	g
Packaging type	BOX	
[mm]	8	mm
Main product function	Fuse term. block	
Product type	Function modules	

Upwards