





Item (Detail view)

2-conductor through terminal block; 4 mm²; lateral marker slots; for DIN-rail 35 x 15 and 35 x 7.5; CAGE CLAMP®

Item no.	291-101	GTN / EAN	4044918618168
Content	1 piece	Order unit	piece
Order quantity	100 piece	Increase in order quantity	(100, 200, 300, 400, ...)
Customer item no.		Customs Tariff no.	85369010000
Customs duty for the country of origin	IN	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company.
Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS
Compliant

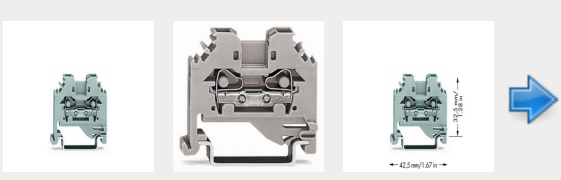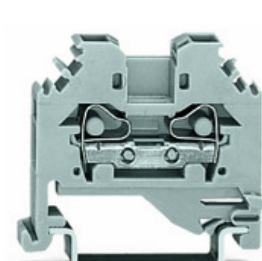

Article details	Approvals	Downloads/Certificates	Accessories
Description			
2-conductor through terminal block; 4 mm ² ; lateral marker slots; for DIN-rail 35 x 15 and 35 x 7.5; CAGE CLAMP®			
Remarks			
Item properties			
Miscellaneous			
Name	Value	Unit	
Connection technology	CAGE CLAMP®		
Actuation type	Operating tool		
Connectable conductor materials	Copper		
Solid conductor	0.08 ... 4 mm ² / 28 ... 12 AWG		
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG		
Strip length	9 ... 18 mm / 0.35 ... 0.39 inch		
Total number of connection points	2		
Total number of potentials	1		
Number of levels	1		
Type of wiring	Side-entry wiring		
Width	6 mm / 0.236 in		
Height from upper-edge of DIN-35 rail	32.5 mm / 1.28 in		
Depth	42.5 mm / 1.673 in		
Design	horizontal		
Type of mounting	Carrier rail 35 x 15		
Marking level	Side marking		
Color	gray		
Insulating material	Polyamide 66 (PA 66)		
Fire load (MJ)	0.108	MJ	
Weight (g)	5.887	g	
Packaging type	BOX		
[mm]	6	mm	
Main product function	Through term. block		
Product type	Through rail-mount term. blocks		

Upwards