



Item (Detail view)


2-conductor through terminal block; 95 mm<sup>2</sup>; lateral marker slots; only for DIN 35 x 15 rail; 2.3 mm thick; copper; POWER CAGE CLAMP



Item no.	285-195	GTN / EAN	4044818452964
Content	1 piece	Order unit	piece
Order quantity	5 piece	Increase in order quantity	(5, 10, 15, 20, ...)
Customer item no.		Customs Tariff no.	85369010000
Customs duty for the country of origin	PL	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS  Compliant

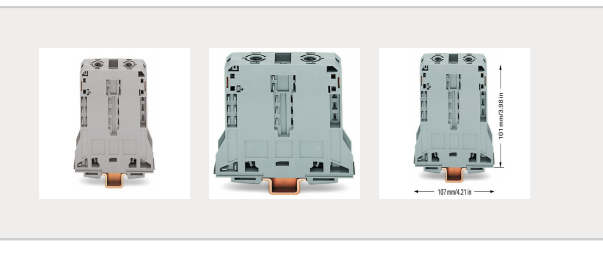

Article details Approvals Downloads/Certificates Accessories

Description 2-conductor through terminal block; 95 mm<sup>2</sup>; lateral marker slots; only for DIN 35 x 15 rail; 2.3 mm thick; copper; POWER CAGE CLAMP

Miscellaneous		
Name	Value	Unit
Safety information 1	swely on DIN-35 x 15 rail	
Connection technology	POWER CAGE CLAMP	
Actuation type	Operating tool	
Connectable conductor materials	Copper	
Solid conductor	25 ... 95 mm <sup>2</sup> / 4 ... 40 AWG	
Fine-stranded conductor	25 ... 95 mm <sup>2</sup> / 4 ... 40 AWG	
Strip length	35 mm / 1.38 inch	
Total number of connection points	2	
Total number of potentials	1	
Number of levels	1	
Type of wiring	Side-entry wiring	
Width	25 mm / 0.984 in	
Height from upper edge of DIN-35 rail	101 mm / 3.976 in	
Depth	107 mm / 4.213 in	
Design	horizontal	
Type of mounting	Carrier rail 35 x 15	
Marking level	Side marking	
Color	gray	
Insulating material	Polysulfide 66 (PA 66)	
Fire load [MJ]	3.564	MJ
Weight [g]	284.291	g
Packaging type	BOX	
[mm]	25	mm
Product Family	POWER CAGE CLAMP	
Main product function	Through term. block	
Product type	High-current terminal blocks	

Upwards