




Item (Detail view)

2-conductor through terminal block; 35 mm<sup>2</sup>; with integrated end plate; side and center marking; only for DIN 35 x 15 rail; 2.3 mm thick; copper; CAGE CLAMP®

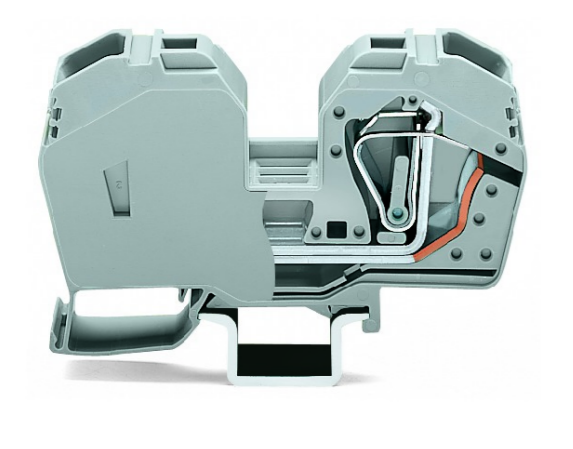

Item no.	285-635	GTN / EAN	40454218713
Content	1 piece	Order unit	piece
Order quantity	15 piece	Increase in order quantity	(15, 30, 45, 60, ...)
Customer item no.		Customs Tariff no.	85369010000
Customs duty for the country of origin	PL	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS  Compliant

Article details Approvals Downloads/Certificates Accessories

Description 2-conductor through terminal block; 35 mm<sup>2</sup>; with integrated end plate; side and center marking; only for DIN 35 x 15 rail; 2.3 mm thick; copper; CAGE CLAMP®

Remarks

Item properties

Miscellaneous		
Name	Value	Unit
Safety information 1	safety on DIN-35 x 15 rail	
Connection technology	CAGE CLAMP®	
Actuation type	Operating tool	
Connectable conductor materials	Copper	
Nominal cross section	35 mm <sup>2</sup>	
Solid conductor	6 ... 35 mm <sup>2</sup> / 6 ... 2 AWG	
Fine-stranded conductor	6 ... 35 mm <sup>2</sup> / 6 ... 2 AWG	
Strip length	23 mm / 0.91 inch	
Total number of connection points	2	
Total number of potentials	1	
Number of levels	1	
Type of wiring	Front-entry wiring	
Width	16 mm / 0.63 in	
Height from upper-edge of DIN-35 rail	53 mm / 2.087 in	
Depth	100 mm / 3.937 in	
Design	horizontal	
Type of mounting	Carrier rail 35 x 15	
Marking level	Center/side marking	
Color	gray	
Insulating material	Polyamide 66 (PA 66)	
Fire load [MJ]	1.078	MJ
Weight [g]	87.389	g
Packaging type	BOX	
[mm]	16	mm
Main product function	Through term. block	
Product type	Through rail-mount term. blocks	

Upwards