



Item (Detail view)


Screwless end stop; 6 mm wide; for WMB markers

Item no.	249-101	GTN / EAN	4500621427766
Content	1 piece	Order unit	piece
Order quantity	25 piece	Increase in order quantity	(25, 50, 75, 100, ...)
Customer item no.		Customs Tariff no.	30269097900
Customs duty for the country of origin	CN	Available	-
List price	On request	Net price	On request
Availability	On request		



Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS Compliant

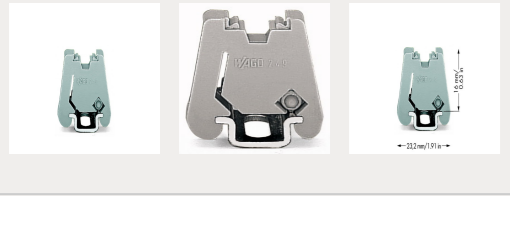

Article details Approvals Downloads/Certificates Accessories

Description		Screwless end stop; 6 mm wide; for WMB markers																																								
Remarks																																										
Item properties		<table border="1"> <thead> <tr> <th colspan="3">Miscellaneous</th> </tr> <tr> <th>Name</th> <th>Value</th> <th>Unit</th> </tr> </thead> <tbody> <tr> <td>Main product function</td> <td>Mounting Accessories</td> <td></td> </tr> <tr> <td>Type of mounting</td> <td>Carrier rail 15 x 5.5</td> <td></td> </tr> <tr> <td>Width</td> <td>6 mm / 0.236 in</td> <td></td> </tr> <tr> <td>Depth</td> <td>23.2 mm / 0.913 in</td> <td></td> </tr> <tr> <td>Height from upper edge of DIN-35 rail</td> <td>16 mm / 0.63 in</td> <td></td> </tr> <tr> <td>Color</td> <td>gray</td> <td></td> </tr> <tr> <td>Fire load (BAU)</td> <td>0.040</td> <td>MJ</td> </tr> <tr> <td>Weight (g)</td> <td>1.58</td> <td>g</td> </tr> <tr> <td>Packaging type</td> <td>BOX</td> <td></td> </tr> <tr> <td>Product type</td> <td>Accessories</td> <td></td> </tr> <tr> <td>[mm]</td> <td>6</td> <td>mm</td> </tr> </tbody> </table>		Miscellaneous			Name	Value	Unit	Main product function	Mounting Accessories		Type of mounting	Carrier rail 15 x 5.5		Width	6 mm / 0.236 in		Depth	23.2 mm / 0.913 in		Height from upper edge of DIN-35 rail	16 mm / 0.63 in		Color	gray		Fire load (BAU)	0.040	MJ	Weight (g)	1.58	g	Packaging type	BOX		Product type	Accessories		[mm]	6	mm
Miscellaneous																																										
Name	Value	Unit																																								
Main product function	Mounting Accessories																																									
Type of mounting	Carrier rail 15 x 5.5																																									
Width	6 mm / 0.236 in																																									
Depth	23.2 mm / 0.913 in																																									
Height from upper edge of DIN-35 rail	16 mm / 0.63 in																																									
Color	gray																																									
Fire load (BAU)	0.040	MJ																																								
Weight (g)	1.58	g																																								
Packaging type	BOX																																									
Product type	Accessories																																									
[mm]	6	mm																																								

Upwards