




Item (Detail view)

4-conductor ground terminal block; suitable for Ex e II applications

Item no.	2001-1427	GTN / EAN	401733299897
Content	1 piece	Order unit	piece
Order quantity	100 piece	Increase in order quantity	(100, 200, 300, 400, ...)
Customer item no.		Customs tariff no.	85369010000
Customs duty for the country of origin	DE	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company. Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

RoHS  Compliant

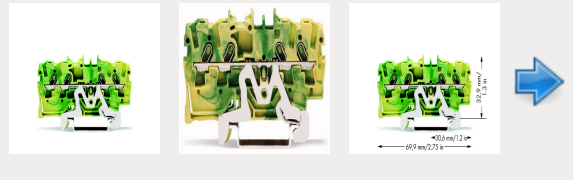

Article details Approvals Downloads/Certificates Accessories

Description		4-conductor ground terminal block; suitable for Ex e II applications	
<b>Remarks</b>			
<b>Item properties</b>			
<b>Miscellaneous</b>			
<b>Name</b>	<b>Value</b>	<b>Unit</b>	
Packaging type	BOX		
Rating (p.e)	IEC/EN 60947-7-2		
Type of wiring	Front-entry wiring		
Total number of connection points	4		
Total number of potentials	1		
Number of levels	1		
Connection technology	Push-in CAGE CLAMP®		
Actuation type	Push-in		
Connectable conductor material	Copper		
Nominal cross section	1.5 mm²		
Solid conductor	0.25 ... 2.5 mm² / 22 ... 14 AWG		
Solid conductor, push-in termination	0.5 ... 2.5 mm² / 20 ... 14 AWG		
Fine-stranded conductor	0.25 ... 2.5 mm² / 22 ... 14 AWG		
Fine-stranded conductor with ferrule, push-in termination, 1	0.75 mm² / 18 AWG		
Strip length	9 ... 11 mm / 0.35 ... 0.43 inch		
Width	4.2 mm / 0.165 inch		
Height from upper edge of DIN 35 rail	32.9 mm / 1.295 inch		
Depth	69.9 mm / 2.752 inch		
Design	horizontal		
Type of mounting	Carrier rail 35 x 15		
Marking level	Center-side marking		
Color	green-yellow		
Insulating material	Polyamide 66 (PA 66)		
Fine lead (MJ)	0.102	MJ	
Weight (g)	8.4	g	
Product Family	TOPJOB® S		
Main product function	GND cond. term. block		
Product type	Through rail-mount term. blocks		

Upwards