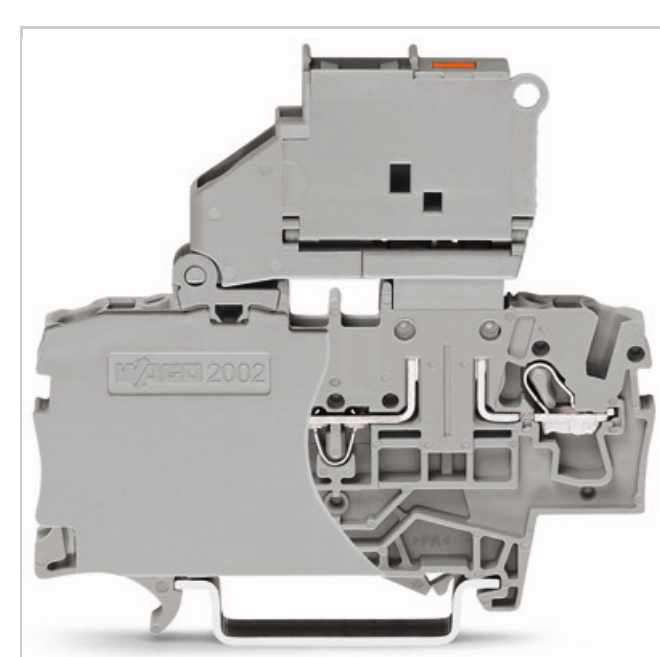
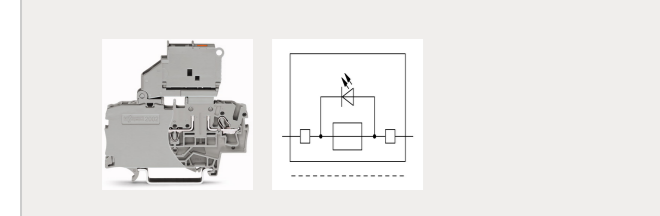



2-conductor fuse disconnect terminal block with pivoting fuse holder, for 5 x 20 mm miniature metric fuse, 230 V, with blown fuse indication by LED


Item no.	2002-1611/1000-836	GTN / EAN	4045654790042
Content	1 piece	Order unit	piece
Order quantity	50 piece	Increase in order quantity	(50, 100, 150, 200, ...)
Customer item no.		Customs tariff no.	85369095990
Customs duty for the country of origin	CN	Available	-
List price	On request	Net price	On request
Availability	On request		

Note: Some items may not be available from your local WAGO company.
Please note that the quantities ordered in the shopping cart are rounded up to the PU (SPU).

 RoHS
 Compliant

[Article details](#)
[Approvals](#)
[Downloads/Certificates](#)
[Accessories](#)
Description 2-conductor fuse disconnect terminal block with pivoting fuse holder, for 5 x 20 mm miniature metric fuse, 230 V, with blown fuse indication by LED

Remarks **Safety information 1:** Electrical ratings are given by the fuse and blown fuse indication.

Item properties
Miscellaneous

Name	Value	Unit
Safety information 2	Leakage current in case of blown fuse: LED 2mA	
Packaging type	BOX	
Standards per	IECEN 60947-7-3	
Rated voltage (III / 3) [V]	250	V
Rated impulse voltage (III / 3) [kV]	6	kV
Rated current [A]	6.3	A
Legend (ratings)	(III / 3) a. Overvoltage category III / Pollution degree 3	
Type of wiring	Front-entry wiring	
Total number of connection points	2	
Total number of potentials	1	
Number of levels	1	
Connection technology	Push-in CAGE CLAMP®	
Actuation type	Push-in	
Connectable conductor materials	Copper	
Nominal cross section	2.5 mm²	
Solid conductor	0.25 ... 4 mm² / 22 ... 12 AWG	
Solid conductor, push-in termination	0.75 ... 4 mm² / 18 ... 12 AWG	
Fine-stranded conductor	0.25 ... 4 mm² / 22 ... 12 AWG	
Fine-stranded conductor with ferrule, push-in termination, f	0.75 mm² / 18 AWG	
Strip length	10 ... 12 mm / 0.39 ... 0.47 inch	
Width	6.2 mm / 0.244 inch	
Height from upper-edge of DIN-35 rail	57.2 mm / 2.252 inch	
Depth	66.1 mm / 2.602 inch	
Design	horizontal	
Type of mounting	Carrier rail 35 x 15	
Marking level	Center-side marking	
Color	gray	
Insulating material	Polyamide 66 (PA 66)	
Fine lead [MJ]	0.287	MJ
Weight [g]	13.65	g
Product Family	TOPJOB® S	
Main product function	Fuse term. block	
Product type	Function modules	

[Upwards](#)