



MSM-226M

Threaded Magnet M6




Data

Housing material	brass, Nickel plated
Potting material	Epoxy, black
Orientation	axially

Magnetic Material	N30H	
Remanence Br	mT	1105
Coercivity HcB	kA/m	836
Coercivity HcJ	kA/m	1274
Energy Product (BH) max.	kJ/m ³	235
Magnetic Moment M	x10 ⁻⁶ Vs cm	14,6
Operating Temperature	°C	-20 to 85
Temperature Coefficient Tk (Br)	%/°C	-0.11

All Dimensions in mm

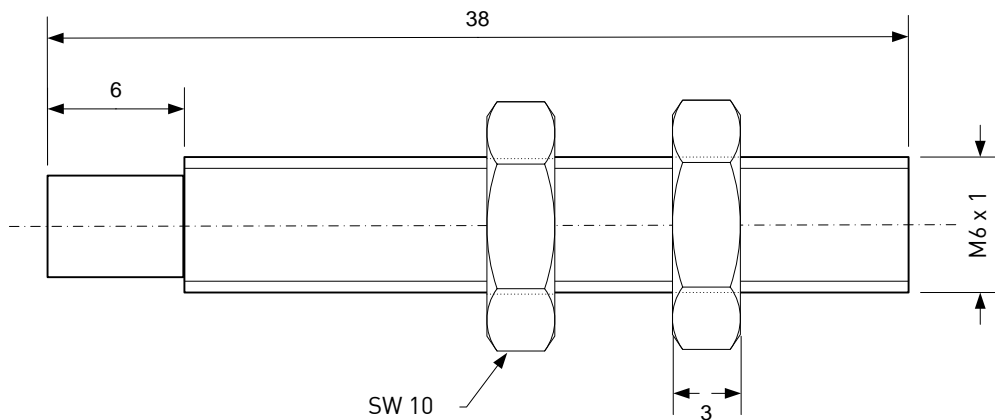

Customized types , other magnet material and high temperature grades available