


## Quartz Crystal

SMD-version


part no.	12.60409
model	KX – 7T
frequency	12.0 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±10 ppm
temperature tolerance -40° ~ +85°C	±15 ppm
load capacitance $C_L$	8 pF
series resistance R1 (ESR) max.	80 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance $C_0$ max.	3.0 pF
drive level max.	200 $\mu$ W
contents of reel	1000 pcs.

### Dimensions:

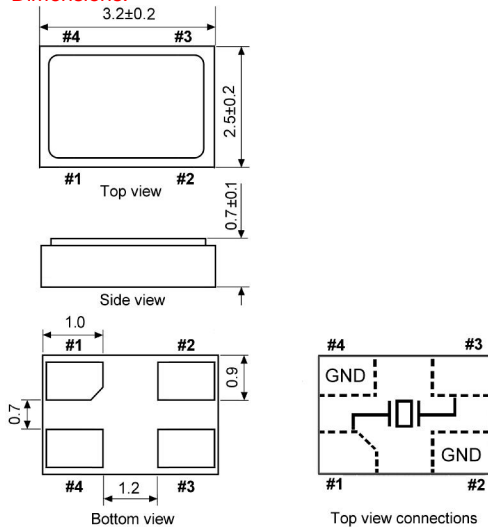


#2 & #4: connected to metal lid


### Suggested soldering pad:

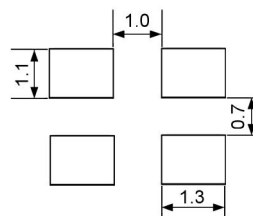

### Reflow soldering condition:

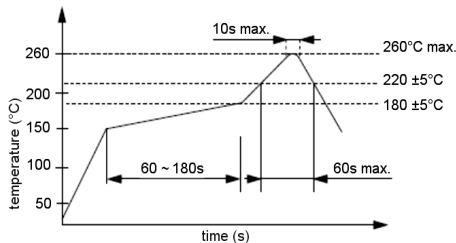

### Tape specification:

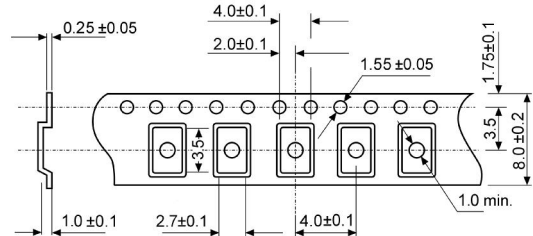

reel diameter 178 mm