


## Quartz Crystal


SMD-version

part no.	12.86588
model	KX – 6T
frequency	15.4560 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±10 ppm
temperature tolerance -40° ~ +85°C	±15 ppm
load capacitance $C_L$	9 pF
series resistance R1 max.	130 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance $C_0$ max.	3.5 pF
drive level max.	100 $\mu$ W
contents of reel	1000 pcs.


### Dimensions (mm):

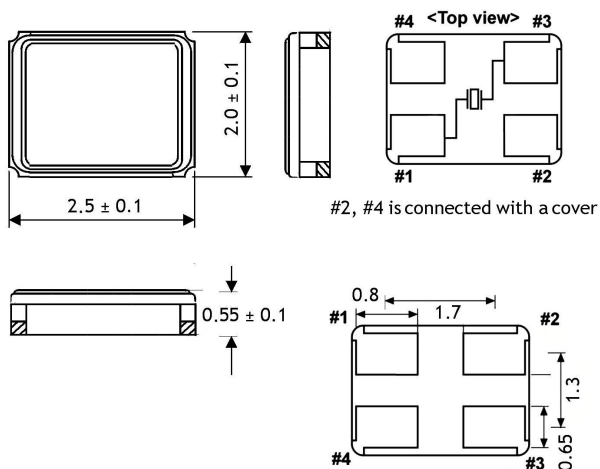


### Suggested soldering pad:

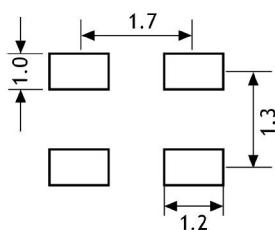

### Reflow soldering condition:

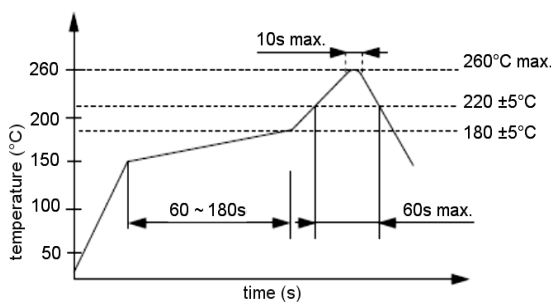

### Tape specification:

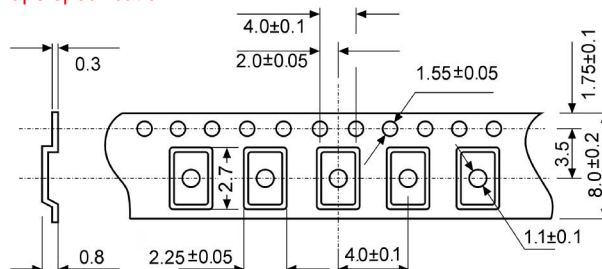

reel diameter 178 mm