


Quartz Crystal


SMD-version

part no.	12.88481
model	KX – 7T
frequency	27.0 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±20 ppm
temperature tolerance -40° ~ +85°C	±30 ppm
load capacitance C _L	12 pF
series resistance R1 (ESR) max.	50 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C ₀ max.	3.0 pF
drive level max.	200 μW
contents of reel	1000 pcs.


Dimensions:

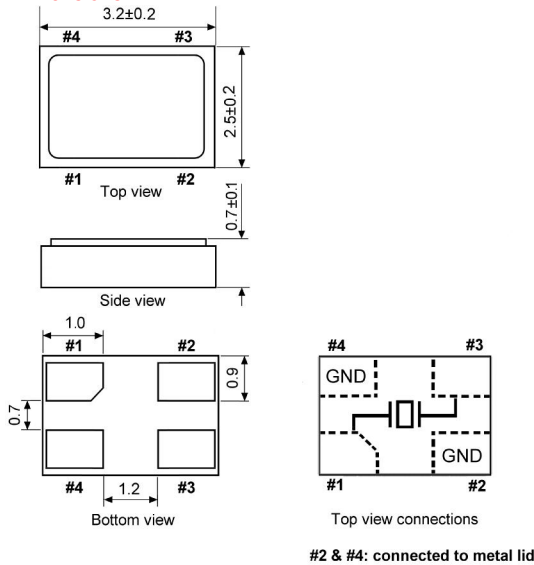


Suggested soldering pad:

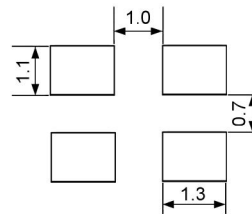

Reflow soldering condition:

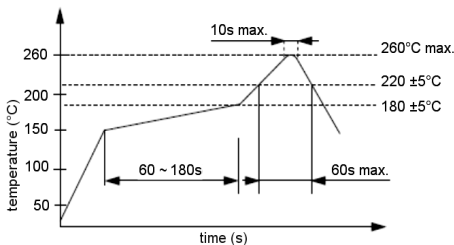

Tape specification:

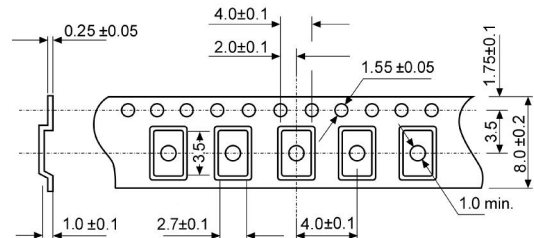

reel diameter 178 mm