





# SYNCHRONOUS GEARMOTOR SP SERIES

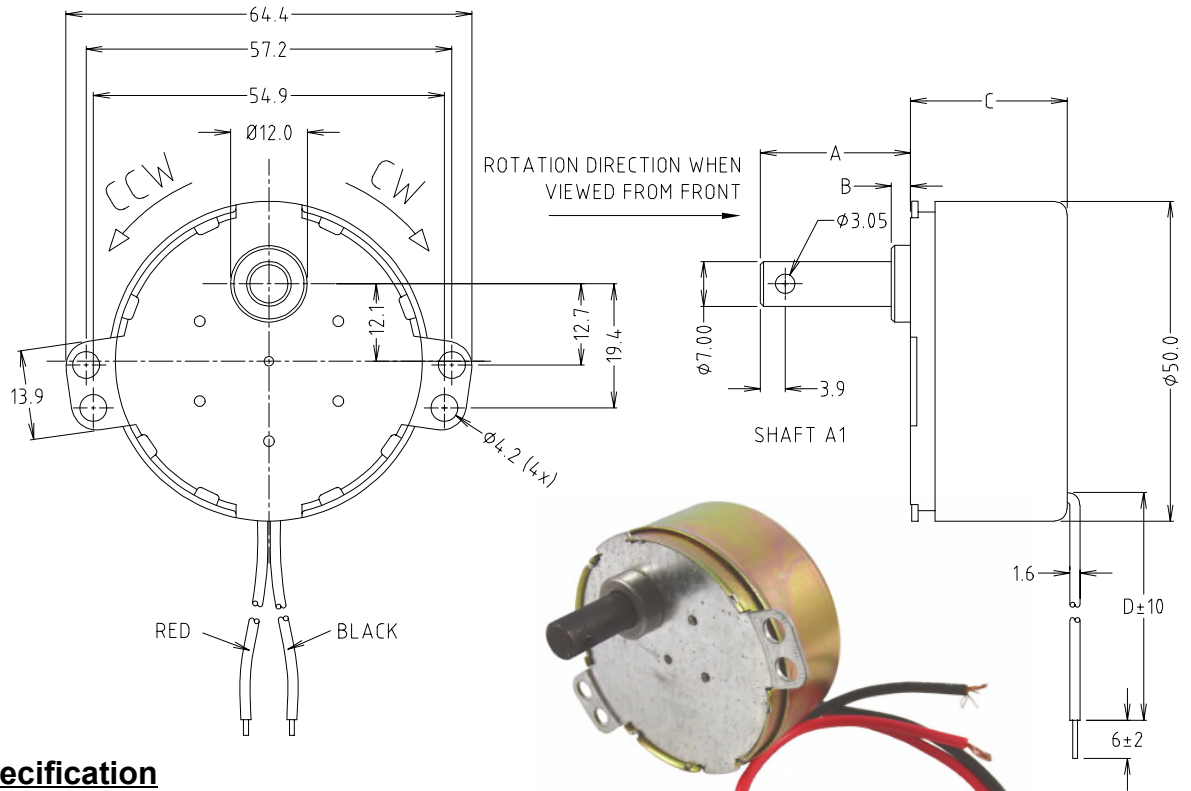

## Specification

Power: 4W  
 Protection Rating: IP50  
 Operating Temperature: -20°...+80°C  
 Operating Voltage: 220-240 VAC  
 Operating Frequency: 50/60Hz  
 Connection: Stranded wires 0.2m  
 Housing: 64.4mm.  
 Shaft Ø: 7mm.  
 RoHS Compliant.

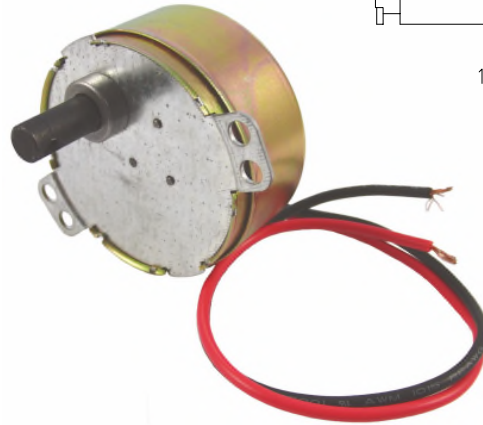

Part No. **FMJ201FB1** Synch Gear motor SP3 Rotation: CW

Speed	2.5/3	R.P.M.
Stall Torque	7.0	kgf-cm

Part No. **FMJ201FJ1** Synch Gear motor SP36 Rotation: CW

Speed	30/36	R.P.M.
Stall Torque	0.6	kgf-cm

Part No. **FMJ201FJ2** Synch Gear motor SP36 Rotation: CCW

Speed	30/36	R.P.M.
Stall Torque	0.6	kgf-cm