


Three Arm Clamping Knobs

Series #3025

- ▶ Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.
- ▶ A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.
- ▶ Perfect for the industrial machinery, medical, general equipment and other industrial applications.
- ▶ Knobs can be decorated or customized to your specific need.
- ▶ Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.
- ▶ Colors available upon request.
- ▶ Please note: Not all variations available are listed below. Please [contact customer service](#) to inquire about all available options.

CHECK INVENTORY

REQUEST A QUOTE

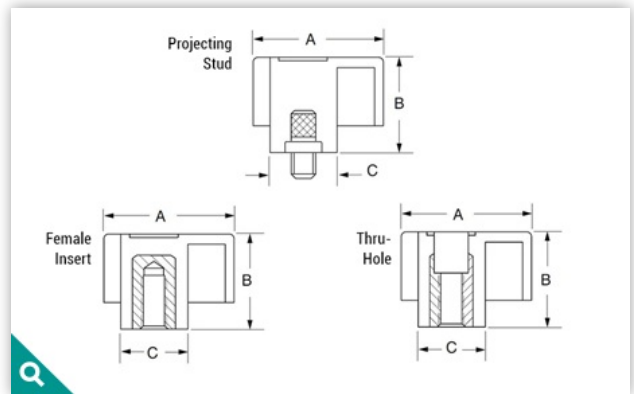

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color	Product Drawing
3025AF	1.13	0.75	0.5	Thermoset	8-32	Projecting Stud	0.375	BLACK	Download
3025AG	1.13	0.75	0.5	Thermoset	1/4-20	Female Insert	0.375	BLACK	Download
3025AH	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.56	BLACK	Download
3025AJ	1.13	0.75	0.5	Thermoset	10-24	Projecting Stud	1.25	BLACK	Download
3025AK	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.50	BLACK	Download
3025AL	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.375	BLACK	Download
3025AN	1.13	0.75	0.5	Thermoset	10-24	Projecting Stud	0.625	BLACK	Download
3025AQ	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.625	BLACK	Download
3025AR	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.44	BLACK	Download
3025AS	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.50	BLACK	Download
3025AT	1.13	0.75	0.5	Thermoset	8-32	Female Insert	0.375	BLACK	Download
3025AU	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	1.50	BLACK	Download
3025AV	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.31	BLACK	Download
3025AZ	1.13	0.75	0.5	Thermoset	10-24	Female Insert	0.375	BLACK	Download
3025BA	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.44	BLACK	Download
3025BB	1.13	0.75	0.5	Thermoset	10-32	Female Insert	0.375	BLACK	Download
3025BC	1.13	0.75	0.5	Thermoset	8-32	Projecting Stud	0.25	BLACK	Download
3025BE	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.75	BLACK	Download
3025BF	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.625	BLACK	Download

3025BB	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.925	BLACK	Download
3025BH	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.75	BLACK	Download
3025BJ	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	1.75	BLACK	Download
3025BM	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	1.00	BLACK	Download
3025CA	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	1.50	BLACK	Download
3025CK	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	2	BLACK	Download
3025CL	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	1.25	BLACK	Download
3025CP	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.375	BLACK	Download
3025CS	1.13	0.75	0.5	Thermoset	10-24	Projecting Stud	0.375	BLACK	Download
3025EH	1.13	1.125	0.5	Thermoset	1/4-20	Projecting Stud	0.50	BLACK	Download
3025EQ	1.13	0.875	0.5	Thermoset	1/4-20	Projecting Stud	0.625	BLACK	Download
3025EW	1.13	0.625	0.5	Thermoset	8-32	Projecting Stud	0.50	BLACK	Download
3025FA	1.13	1.125	0.5	Thermoset	10-32	Projecting Stud	1.00	BLACK	Download
3025FE	1.13	0.75	0.5	Thermoset	10-32	Female Insert	0.375	WHITE	Download
3025FS	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.50	BLACK	Download
3025FX	1.13	0.625	0.5	Thermoset	1/4-20	Projecting Stud	1.125	BLACK	Download
3025FY	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.50	BLACK	Download
3025GC	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.50	RED	Download
3025GF	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	1.00	BLACK	Download
3025GH	1.13	0.75	0.5	Thermoset	10-32	Thru-Hole		BLACK	Download
3025GJ	1.13	0.75	0.5	Thermoset	1/4-20	Thru-Hole		BLACK	Download
3025GK	1.13	0.75	0.5	Thermoset	1/4-20	Projecting Stud	0.25	BLACK	Download
3025GL	1.13	0.75	0.5	Thermoset	M6	Projecting Stud	0.31	BLACK	Download
3025GM	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.875	BLACK	Download
3025GN	1.13	0.625	0.5	Thermoset	8-32	Projecting Stud	0.75	BLACK	Download
3025GP	1.13	0.75	0.5	Thermoset	8-32	Female Insert	0.375	WHITE	Download
3025GQ	1.13	0.625	0.5	Thermoset	1/4-20	Projecting Stud	0.75	BLACK	Download
3025GS	1.13	1.125	0.5	Thermoset	10-32	Projecting Stud	0.625	BLACK	Download
3025GT	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	0.375	WHITE	Download
3025GV	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	1.25	BLACK	Download
3025GY	1.13	0.75	0.5	Thermoset	10-32	Projecting Stud	1.00	BLACK	Download
3025GZ	1.13	0.625	0.5	Thermoset	10-32	Projecting Stud	1.25	BLACK	Download
3025HB	1.13	0.75	0.5	Thermoset	M6	Projecting Stud		BLACK	
3025HN	1.13	0.75	0.5	Thermoset	M4	Female Insert		BLACK	
3025HP	1.13	0.75	0.5	Thermoset	M6	Female Insert		BLACK	
3025HQ	1.13	0.75	0.5	Thermoset	M4	Projecting Stud		BLACK	
3025HR	1.13	0.75	0.5	Thermoset	M4	Projecting Stud		BLACK	
3025HS	1.13	0.75	0.5	Thermoset	M6	Projecting Stud		BLACK	

PRODUCTS

[Knobs](#)
[Handles](#)
[Electronic Enclosures](#)
[Hex Hybrid Standoffs](#)
[Two-Shot / Soft Touch](#)
[Frac Balls](#)
[Cable Glands](#)
[Rubber Grommets](#)
[Custom Molding](#)

RESOURCES

[Engineering Specifications](#)
[Distributor Listing](#)
[Sales Representative Listing](#)

COMPANY

[About Us](#)
[Capabilities](#)
[Certifications](#)
[Contact Us](#)
[Blog](#)
[Careers](#)

QUESTIONS ?

1 + 1 = *

SEND

