



## Powerful Brands from Wiha.


Proturn® 3K  
Proturn® 1K



**wiha**   
Premium Tools

# Wiha Proturn® 3K.

The handy all-rounder.

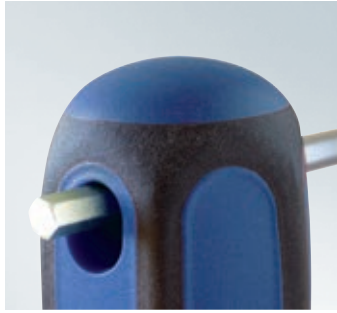

The Wiha Proturn® 3K is a screwdriver with a multi-component handle. Users in both industry and DIY appreciate the tool's features and versatility. The convincing handle design with hard and soft zones allows an optimum of usability. Due to this material combination, maximum torque transfer with a minimum effort is provided.

An additional characteristic is the practical hanging hole – ideal to show the screwdriver on commercially available display hooks. The blades are made of high-quality chrome-vanadium-molybdenum steel, through hardened and chrome plated. The precision machined black tip guarantees dimensional accuracy over many years.



Wiha Proturn® 3K screwdrivers are available in all common dimensions and in different sets.



## Proturn® 3K.

- Convincing handle design with hard and soft zones and practical hanging hole
- Enables maximum torque transfer with minimum effort
- Suitable for users in industry, trade and DIY
- Blades made of high-quality CVM steel, through hardened and chrome plated
- Precision machined black tip
- Manufactured acc. to all relevant DIN/ISO standards

**For slotted and Phillips screws.**



**450N** Proturm® 3K slotted screwdriver.  
 Blade: **Round blade.**  
 High quality CVM steel, through hardened.  
 Chrome plated with precision black tip.  
 Handle: Proturm® 3K multi-component handle with hanging hole.  
 Standards: DIN 5265, ISO 2380.  
 Application: For multipurpose use in industrial and trade applications.

Order-No.	⌀	Øi	↔	●i	↔	↔	↔
27612	0.4	2.5	75	2.5	86	26	10
25436	0.5	3.0	80	3.0	86	26	10
27768	0.5	3.0	100	3.0	86	26	10
27769	0.5	3.0	150	3.0	86	26	10
25437	0.6	3.5	100	3.5	100	30	10
25438	0.8	4.0	100	4.0	107	33	10
27770	0.8	4.5	80	4.5	107	33	10
27611	0.8	4.5	125	4.5	107	33	10
25439	1.0	5.5	125	5.5	119	37	10
27771	1.0	6.0	100	6.0	119	37	10
27772	1.0	6.0	150	6.0	119	37	10
25440	1.2	6.5	150	6.5	119	37	10
25441	1.2	8.0	175	8.0	119	37	10
25442	1.6	10.0	200	8.0	119	37	10

**For Pozidriv and TORX® screws.**



**452N** Proturm® 3K Pozidriv screwdriver.  
 Blade: **Round blade.**  
 High quality CVM steel, through hardened.  
 Chrome plated with precision black tip.  
 Handle: Proturm® 3K multi-component handle with hanging hole.  
 Standards: ISO 8764.  
 Application: For multipurpose use in industrial and trade applications.

Order-No.	⊕	↔	●i	↔	↔	↔
25448	PZ0	60	3.0	86	26	10
27776	PZ0	100	3.0	86	26	10
25449	PZ1	80	4.5	107	33	10
27777	PZ1	100	4.5	107	33	10
25450	PZ2	100	6.0	119	37	10
27778	PZ2	150	6.0	119	37	10
25451	PZ3	150	8.0	119	37	10



**451N** Proturm® 3K Phillips screwdriver.  
 Blade: **Round blade.**  
 High quality CVM steel, through hardened.  
 Chrome plated with precision black tip.  
 Handle: Proturm® 3K multi-component handle with hanging hole.  
 Standards: ISO 8764.  
 Application: For multipurpose use in industrial and trade applications.

Order-No.	⊕	↔	●i	↔	↔	↔
25443	PH0	60	3.0	86	26	10
27773	PH0	100	3.0	86	26	10
25444	PH1	80	4.5	107	33	10
27774	PH1	100	4.5	107	33	10
25445	PH2	100	6.0	119	37	10
27775	PH2	150	6.0	119	37	10
25475	PH3	150	8.0	119	37	10



**455N** Proturm® 3K TORX® screwdriver.  
 Blade: **Round blade.**  
 High quality CVM steel, through hardened.  
 Chrome plated with precision black tip.  
 Handle: Proturm® 3K multi-component handle with hanging hole.  
 Application: For multipurpose use in industrial and trade applications.

Order-No.	⊕	↔	●i	↔	↔	↔
25452	T6	60	3.5	86	26	10
25453	T7	60	3.5	86	26	10
25454	T8	60	3.5	86	26	10
25455	T9	60	4.0	100	30	10
25456	T10	80	4.0	100	30	10
25457	T15	80	4.0	107	33	10
25458	T20	100	4.0	107	33	10
25459	T25	100	4.5	107	33	10
27610	T27	115	5.5	119	37	10
25460	T30	115	6.0	119	37	10
25461	T40	130	7.0	119	37	10

# Wiha Proturn® 3K.

The handy all-rounder.

## Bit holder. Slotted/Phillips screwdriver set.



### 484N Proturn® 3K Bit holder 1/4", magnetic.

Shaft: Made of CV steel, through hardened, nickel plated.

Bit retainer: Magnetic, holds bit and screw.

Standards: DIN 3126-D 6,3 / ISO 1173.

Handle: Proturn® 3K multi-component handle with hanging hole.

Order-No.	1/4"	125	107	33	
25550					10

## Sets.



### 450N ZK6 Proturn® 3K slotted/Pozidriv screwdriver set, 6 pcs.

Blade: **Round blade.**

High quality CVM steel, through hardened.

Chrome plated with precision black tip.

Handle: Proturn® 3K multi-component handle with hanging hole.

Standards: DIN 5265, ISO 2380, ISO 8764.

Application: For multipurpose use in industrial and trade applications.

Order-No.	Series					
25447						1
① 450N	3.0x80	4.0x100	5.5x125	6.5x150		
⊕ 452N	PZ1x80	PZ2x100				



### 450N HK6 Proturn® 3K slotted/Phillips screwdriver set, 6 pcs.

Blade: **Round blade.**

High quality CVM steel, through hardened.

Chrome plated with precision black tip.

Handle: Proturn® 3K multi-component handle with hanging hole.

Standards: DIN 5265, ISO 2380, ISO 8764.

Application: For multipurpose use in industrial and trade applications.

Order-No.	Series					
25446						1
① 450N	3.0x80	4.0x100	5.5x125	6.5x150		
⊕ 451N	PH1x80	PH2x100				



### 455N K6 Proturn® 3K TORX® screwdriver set, 6 pcs.

Blade: **Round blade.**

High quality CVM steel, through hardened.

Chrome plated with precision black tip.

Handle: Proturn® 3K multi-component handle with hanging hole.

Application: For multipurpose use in industrial and trade applications.

Order-No.	Series						
25462							1
⊕ 455N	T10	T15	T20	T25	T30	T40	



# Wiha Proturm® 1K.

The multi-use screwdriver.



The Wiha Proturm® 1K series screwdrivers are extremely economic. They have been developed to fulfil many industrial and trade applications. The handy, rounded handles are made of impact resistant polypropylene.

All blades are manufactured from high-quality chrome-vanadium-molybdenum steel, through hardened and have a precision black tip. Hardness, torque and dimensional accuracy of each screwdriver meet all DIN/ISO specifications.

Wiha Proturm® 1K screwdrivers are offered in all popular dimensions, including the Proturm® 1K Stubby for working in confined spaces – at an unbeatable, attractive price.



## Proturm® 1K.

- Handy, rounded handle made of polypropylene
- Developed for many industrial and trade applications
- Blades made of high-quality CVM steel, through hardened and chromium plated
- Precision machined black tip
- Manufactured acc. to all relevant DIN/ISO standards

## For slotted screws.



**4460**

### Proturm® 1K slotted screwdriver.

Blade:

**Round blade.**

High quality CVM steel, through hardened. Chrome plated with precision black tip.

Handle:

Proturm® 1K handle in blue polypropylene.

Standards:

DIN 5265, ISO 2380.

Application:

An ergonomic screwdriver for everyday applications.

Order-No.	⌀	⌀	↔	●	↔	↔	↔
28200	0.4	2.5	75	2.5	80	24	10
27780	0.5	3.0	80	3.0	80	24	10
27781	0.5	3.0	100	3.0	80	24	10
27782	0.5	3.0	150	3.0	80	24	10
27783	0.6	3.5	100	3.5	90	27	10
27784	0.8	4.0	100	4.0	100	30	10
27785	0.8	4.5	80	4.5	100	30	10
27786	0.8	4.5	125	4.5	100	30	10
27787	1.0	5.5	125	5.5	110	34	10
27788	1.0	6.0	100	6.0	110	34	10
27789	1.0	6.0	150	6.0	110	34	10
27790	1.2	6.5	150	6.5	110	34	10
27791	1.2	8.0	175	8.0	110	34	10
27792	1.6	10.0	200	8.0	110	34	10

# Wiha Proturn® 1K.

The multi-use screwdriver.

## For Phillips and Pozidriv screws.



### 4461 Proturn® 1K Phillips screwdriver.

Blade: **Round blade.**

High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturn® 1K handle in blue polypropylene.

Standards: ISO 8764.

Application: An ergonomic screwdriver for everyday applications.

Order-No.	⊕	➤	●	➤	➤	➤
27793	PH0	60	3.0	80	24	10
27794	PH0	100	3.0	80	24	10
27795	PH1	80	4.5	100	30	10
27796	PH1	100	4.5	100	30	10
27797	PH2	100	6.0	110	34	10
27798	PH2	150	6.0	110	34	10
27799	PH3	150	8.0	110	34	10



### 4462 Proturn® 1K Pozidriv screwdriver.

Blade: **Round blade.**

High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturn® 1K handle in blue polypropylene.

Standards: ISO 8764.

Application: An ergonomic screwdriver for everyday applications.

Order-No.	⊕	➤	●	➤	➤	➤
27800	PZ0	60	3.0	80	24	10
27801	PZ0	100	3.0	80	24	10
27802	PZ1	80	4.5	100	30	10
27804	PZ1	100	4.5	100	30	10
27805	PZ2	100	6.0	110	34	10
27806	PZ2	150	6.0	110	34	10
27807	PZ3	150	8.0	110	34	10

## Stubby screwdrivers.



### 4460 Proturn® 1K slotted screwdriver.

Blade: **Short round blade.**

High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturn® 1K handle in blue polypropylene.

Standards: DIN 5265, ISO 2380, handle based on DIN 5268 - style K.

Application: For working in confined spaces.

Order-No.	⊖	⊖	➤	●	➤	➤	➤
27832	0.8	4.0	25	4.0	50	32	10
27833	1.0	5.5	25	5.0	50	32	10
27834	1.2	6.5	25	6.5	50	32	10
27835	1.2	8.0	25	8.0	50	32	10



### 4461 Proturn® 1K Phillips screwdriver.

Blade: **Short round blade.**

High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturn® 1K handle in blue polypropylene.

Standards: DIN 5265, ISO 2380, handle based on DIN 5268 - style K.

Application: For working in confined spaces.

Order-No.	⊕	➤	●	➤	➤	➤
27836	PH01	25	4.5	50	32	10
27837	PH02	25	6.0	50	32	10



### 4462 Proturn® 1K Pozidriv screwdriver.

Blade: **Short round blade.**

High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturn® 1K handle in blue polypropylene.

Standards: DIN 5265, ISO 2380, handle based on DIN 5268 - style K.

Application: For working in confined spaces.

Order-No.	⊕	➤	●	➤	➤	➤
27839	PZ01	25	4.5	50	32	10
27840	PZ02	25	6.0	50	32	10

**For TORX® and hex nuts.**



**4465 Proturm® 1K TORX® screwdriver.**

Blade: **Round blade.**  
High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturm® 1K handle in blue polypropylene.

Application: An ergonomic screwdriver for everyday applications.

Order-No.	⊕	←→	●	←→	←→	←→
27821	T6	60	3.5	80	24	10
27822	T7	60	3.5	80	24	10
27823	T8	60	3.5	80	24	10
27824	T9	60	4.0	90	27	10
27825	T10	80	4.0	90	27	10
27826	T15	80	4.0	100	27	10
27827	T20	100	4.0	100	30	10
27828	T25	100	4.5	100	30	10
27829	T27	115	5.5	110	34	10
27830	T30	115	6.0	110	34	10
27831	T40	130	7.0	110	34	10



**4484 Proturm® 1K bit holder 1/4", magnetic.**

Shaft: Made of CV steel, through hardened, nickel plated.

Bit retainer: Magnetic, holds bit and screw.

Standards: DIN 3126-D 6,3 / ISO 1173.

Handle: Proturm® 1K handle in blue polypropylene.

Order-No.	⊙	←→	←→	←→	←→
28204	1/4"	125	106	30	10



**Sets.**



**4460 HK6 Proturm® 1K slotted/Phillips screwdriver set, 6 pcs.**

Blade: **Round blade.**  
High quality CVM steel, through hardened.  
Chrome plated with precision black tip.

Handle: Proturm® 1K handle in blue polypropylene.

Standards: DIN 5265, ISO 2380, ISO 8764.

Application: An ergonomic screwdriver for everyday applications.

Order-No.	Series	←→	←→	←→	←→
27842					1
① 4460	3.5x100 4.5x125 5.5x125 6.5x150				
⊕ 4461	PH1x80 PH2x100				



**4460 ZK6 Proturm® 1K slotted/Poizdriv screwdriver set, 6 pcs.**

Blade: **Round blade.**

Standards: DIN 5265, ISO 2380, ISO 8764.

Order-No.	Series	←→	←→	←→	←→
27843					1
① 4460	3.5x100 4.5x125 5.5x125 6.5x150				
⊕ 4462	PZ1x80 PZ2x100				




**4465 K6 Proturm® 1K TORX® screwdriver set, 5 pcs.**

Blade: **Round blade.**

Order-No.	Series	←→	←→	←→	←→	←→
27844						1
⊕ 4465	T10 T15 T20 T25 T30 T40					

# Wiha Proturn® 3K electric.

The premier insulated VDE screwdriver.

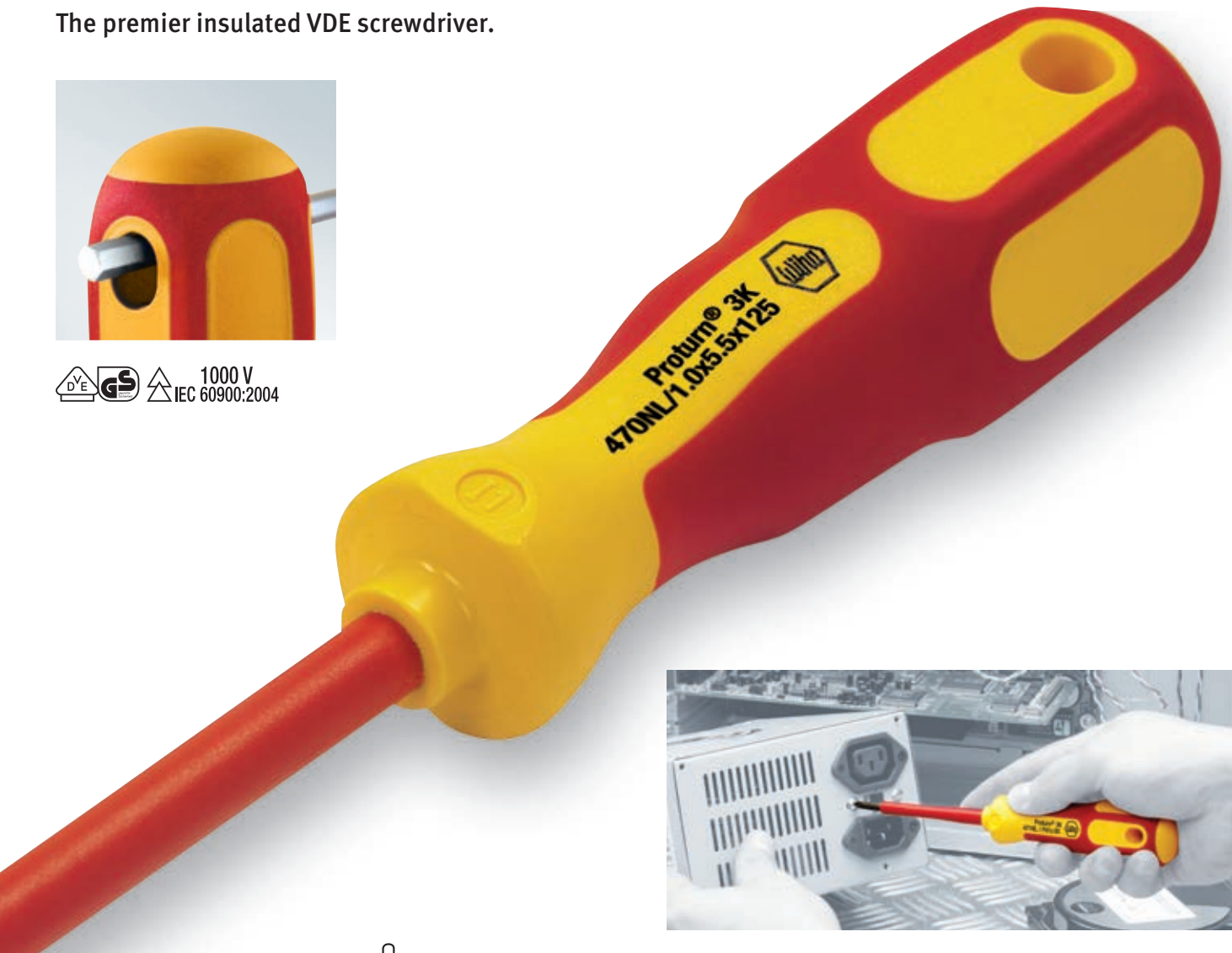

The Proturn® 3K electric insulated VDE screwdriver combines excellent functionality along with an attractive price. The ergonomic multi-component handle with the practical hanging hole provides a firm hold and maximum torque. The blade is made of high-quality chrome-vanadium-molybdenum steel, through hardened with a black oxide tip for exceptional strength and durability.

The blade insulation is moulded directly onto the blade, making handle and blade inseparable. For user safety and comfort, each screwdriver is tested in a water bath at 10,000 volts. This guarantees maximum protection against electrical shock, when working on live equipment up to 1000 V AC resp. 1500 V DC.



## Proturn® 3K electric.

- Comfortable multi-component handle with practical hanging hole makes the tool comfortable to use all day
- Blades made of high-quality CVM steel, through hardened, black oxide finish
- Insulation moulded directly onto blade
- Each screwdriver is tested in accordance with IEC 60900:2004
- For working on live equipment up to 1000 V AC/ 1500 V DC

## For slotted screws.



470N

Proturn® 3K electric VDE slotted screwdriver. Individually tested protective insulation 1,000 V AC, VDE and GS tested.

Blade: High quality CVM steel, through hardened, black finish. Insulation moulded directly onto blade.

Handle: Proturn® 3K electric insulated multi-component handle with hanging hole.

Standards: DIN 7437, DIN 5264, ISO 2380. Manufactured acc. to IEC 60900:2004.

Application: For electrical applications up to 1000 V AC.

Order-No.	⌀	⌀i	↔	↔	↔	↔
25463	0.4	2.5	75	86	26	10
25464	0.5	3.0	100	86	26	10
25465	0.6	3.5	100	100	30	10
25466	0.8	4.0	100	107	33	10
25467	1.0	4.5	125	107	33	10
25468	1.0	5.5	125	119	37	10
25469	1.2	6.5	150	119	37	10
25470	1.2	8.0	175	119	37	10
27845	1.6	10.0	200	119	37	10





**For Phillips, Pozidriv and TORX® screws.**



**471N** Proturm® 3K electric VDE Phillips screwdriver.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Blade: High quality CVM steel, through hardened, black finish.  
Insulation moulded directly onto blade.  
Handle: Proturm® 3K electric insulated multi-component handle with hanging hole.  
Standards: ISO 8764.  
Manufactured acc. to IEC 60900:2004.  
Application: For electrical applications up to 1000 V AC.

Order-No.	+	←→	←→	←→	←→
27689	PH0	60	86	26	10
25471	PH1	80	107	33	10
25472	PH2	100	119	37	10
25474	PH3	150	119	37	10



**472N** Proturm® 3K electric VDE Pozidriv screwdriver.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: DIN 7438, ISO 8764.  
Manufactured acc. to IEC 60900:2004.

Order-No.	⊕	←→	←→	←→	←→
27849	PZ1	80	107	33	10
27850	PZ2	100	119	37	10
27851	PZ3	150	119	37	10



**475N** Proturm® 3K electric VDE TORX® screwdriver.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	⊕	←→	●	←→	←→	←→
27852	T6	60	3.0	86	26	10
27853	T7	60	3.5	86	26	10
27854	T8	60	3.5	86	26	10
27855	T9	60	4.0	100	30	10
27856	T10	60	4.0	100	30	10
27857	T15	80	4.0	107	30	10
27858	T20	80	4.0	107	33	10
27859	T25	80	4.5	107	33	10
27860	T30	100	6.0	119	33	10
27861	T40	150	7.0	119	37	10

**Sets.**



**470N K6** Proturm® 3K electric VDE slotted/Phillips screwdriver set, 6 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series	←→	←→	←→	←→
25473					1
⓪	470N	3.0x100	4.0x100	5.5x125	6.5x150
⊕	471N	PH1x80	PH2x100		



**470N ZK6** Proturm® 3K electric VDE slotted/Pozidriv screwdriver set, 6 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series	←→	←→	←→	←→
36466					1
⓪	470N	3.0x100	4.0x100	5.5x125	6.5x150
⊕	472N	PZ1x80	PZ2x100		



With voltage tester



**470N K601** Proturm® 3K electric VDE slotted/Phillips screwdriver set with  
voltage tester, 6 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series	←→	←→	←→
28184				1
⓪	470N	2.5x75	4.0x100	5.5x125
⊕	471N	PH1x80	PH2x100	
⓪	255-3	3.0	voltage tester	

# Wiha Proturm® 1K electric.

The practical, insulated VDE screwdriver.



For slotted and Phillips screws.



**470** Proturm® 1K electric VDE slotted screwdriver. Individually tested protective insulation 1,000 V AC, VDE and GS tested.

Blade: High quality CVM steel, through hardened, black finish. Insulation moulded directly onto blade.

Handle: Proturm® 1K electric fully insulated VDE handle.

Standards: DIN 7437, DIN 5264, ISO 2380.

Manufactured acc. to IEC 60900:2004.

Application: For electrical applications up to 1000 V AC.

Order-No.	⌀	⌀i	↔	↔	↔	↔
06179	0.4	2.5	75	80	24	10
06180	0.5	3.0	100	80	24	10
06181	0.6	3.5	100	90	27	10
06182	0.8	4.0	100	100	30	10
06183	1.0	4.5	125	100	30	10
06184	1.0	5.5	125	110	34	10
06186	1.2	6.5	150	110	34	10
06187	1.2	8.0	175	110	34	10
06188	1.6	10.0	200	110	34	10



**Proturm® 1K electric.**

- VDE insulated screwdriver, made of impact resistant polypropylene
- Blades made of high-quality CVM steel, through hardened, black oxide finish
- Each individual tool is tested to 10,000 volts acc. to IEC 60900:2004
- Insulation moulded directly onto blade to ensure safe and long lasting protection
- Suitable for use on live lines up to 1000 V AC/ 1500 V DC

In no other workplace is it more important to use safe screwdrivers than when working on voltage applications. Our insulated Proturm® 1K electric screwdrivers are manufactured according to international IEC 60900:2004 standards and their insulation properties are tested in a 10,000 volt water bath. The handle is made of impact resistant polypropylene. The blade is made of high-quality chrome-vanadium-molybdenum steel, through hardened with a black oxide finish tip.

Thanks to the use of the best materials and manufacturing technology, with a Proturm® 1K electric you get a quality product.



**471** Proturm® 1K electric VDE Phillips screwdriver. Individually tested protective insulation 1,000 V AC, VDE and GS tested.

Standards: DIN 7438, ISO 8764.

Manufactured acc. to IEC 60900:2004.

Order-No.	⊕	↔	↔	↔	↔
06175	PH 0	60	80	24	10
06176	PH 1	80	100	30	10
06177	PH 2	100	110	34	10
06178	PH 3	150	110	34	10



**For Pozidriv and TORX® screws. Slotted/Phillips set.**



**472** Proturm® 1K electric VDE Pozidriv screwdriver.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: DIN 7438, ISO 8764. Manufactured acc. to IEC 60900:2004.

Order-No.					
06914	PZ1 80	80	30		10
06915	PZ2 100	100	34		10
07316	PZ3 150	110	34		10



**475** Proturm® 1K electric VDE TORX® screwdriver.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.												
27846	T6 60	3.0	80	24							10	
27847	T7 60	3.5	80	24							10	
27848	T8 60	3.5	80	24							10	
27864	T9 60	4.0	90	27							10	
27865	T10 60	4.0	90	27							10	
27866	T15 80	4.0	100	27							10	
27867	T20 80	4.0	100	30							10	
27868	T25 80	4.5	100	30							10	
27869	T30 100	6.0	110	34							10	
27870	T40 150	7.0	110	34							10	



**470 K6 01** Proturm® 1K electric VDE slotted/Phillips screwdriver set, 6 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series		
27871			1
	① 470	3.0x100 4.0x100 5.5x125 6.5x150	
	⊕ 471	PH1x80 PH2x100	

**Sets.**



With voltage tester



**470 K6** Proturm® 1K electric VDE slotted/Phillips screwdriver set with voltage tester, 6 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series		
06189			1
	① 470	2.5x75 4.0x100 5.5x125	
	⊕ 471	PH1x80 PH2x100	
	① 255-3	3.0 voltage tester	



With voltage tester



**470 K7** Proturm® 1K electric VDE slotted/Phillips screwdriver set with voltage tester, 7 pcs.  
Individually tested protective insulation 1,000 V AC,  
VDE and GS tested.

Standards: Manufactured acc. to IEC 60900:2004.

Order-No.	Series		
23561			1
	① 470	2.5x75 4.0x100 5.5x125 6.5x150	
	⊕ 471	PH1x80 PH2x100	
	① 255-3	3.0 voltage tester	



**Wiha world-wide.**

**70 years.**  
Innovation.  
Quality.  
Reliability.

*wiha*



Premium Tools



Your stockist:

**wiha**   
Premium Tools

**Wiha Werkzeuge GmbH**  
Obertalstraße 3-7  
D-78136 Schonach/Germany  
Tel. +49 7722 959-0  
Fax +49 7722 959-159  
info@wiha.com  
[www.wiha.com](http://www.wiha.com)

