




VGRD Black or Red Vinyl PVC Round

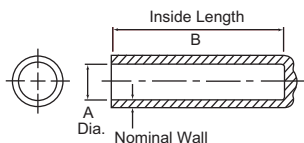


Features:

- Flexible material can stretch onto slightly larger dimensions for a snug fit without tearing, splitting or shredding
- Special order colors and materials available

Item No.	Material & Color	A		B		Pack Qty.	Bulk Pack Qty.
		In	mm	In	mm		
VGRD07504000A	Black PVC	0.750	19.1	4.000	101.6	1	500
VGRD07504000B	Textured Black PVC	0.750	19.1	4.000	101.6	1	500
VGRD07505000A	Black PVC	0.750	19.1	5.000	127.0	1	250
VGRD07505000B	Textured Black PVC	0.750	19.1	5.000	127.0	1	250
VGRD07505000D	PVC Red	0.750	19.1	5.000	127.0	1	250
VGRD08124500A	Textured Black PVC	0.812	20.6	4.500	114.3	1	400
VGRD08434500B	Textured Black PVC	0.843	21.4	4.500	114.3	1	400
VGRD08754000B	Textured Black PVC	0.875	22.2	4.000	101.6	1	400
VGRD08755000A	Black PVC	0.875	22.2	5.000	127.0	1	300
VGRD08755000B	Textured Black PVC	0.875	22.2	5.000	127.0	1	150
VGRD08755000C	PVC Red	0.875	22.2	5.000	127.0	1	300
VGRD09374000A	Black PVC	0.937	24.7	4.000	101.6	1	300
VGRD09374000B	Textured Black PVC	0.937	24.7	4.000	101.6	1	300
VGRD10004000A	Black PVC	1.000	25.4	4.000	101.6	1	400
VGRD10004500A	Black PVC	1.000	25.4	4.500	114.3	1	300

Item No.	Material & Color	A		B		Pack Qty.	Bulk Pack Qty.
		In	mm	In	mm		
VGRD10005000A	Black PVC	1.000	25.4	5.000	127.0	1	250
VGRD10005000B	Textured Black PVC	1.000	25.4	5.000	127.0	1	300
VGRD10005000C	PVC Red	1.000	25.4	5.000	127.0	1	300
VGRD10624000A	Black PVC	1.062	27.0	4.000	101.6	1	300
VGRD10624500B	Textured Black PVC	1.062	27.0	4.500	114.3	1	300
VGRD11254000B	Textured Black PVC	1.125	28.6	4.000	101.6	1	250
VGRD11255000A	Black PVC	1.125	28.6	5.000	127.0	1	200
VGRD11255000B	Textured Black PVC	1.125	28.6	5.000	127.0	1	200
VGRD12504500A	Black PVC	1.250	31.8	4.500	114.3	1	250
VGRD12504500C	PVC Red	1.250	31.8	4.500	114.3	1	200
VGRD12505000B	Textured Black PVC	1.250	31.8	5.000	127.0	1	200
VGRD15004000A	Black PVC	1.500	38.1	4.000	101.6	1	200
VGRD15004500B	Textured Black PVC	1.500	38.1	4.500	114.3	1	200
VGRD17504000A	Black PVC	1.750	44.4	4.000	101.6	1	150

VGN Black Vinyl PVC Round Finger Grasp

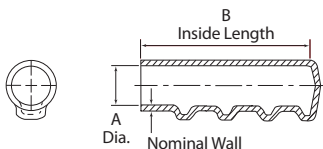


Features:

- Ideal for applications requiring a uniform finger grasp
- Flexible material can stretch onto slightly larger dimensions for a snug fit without tearing, splitting or shredding
- Special order colors and textured materials available

Item No.	A		B		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm		
VGN10004000A	1.000	25.4	4.000	101.6	1	350
VGN07504500A	0.750	19.1	4.500	114.3	1	200
VGN10004500A	1.000	25.4	4.500	114.3	1	300
VGN08755000A	0.875	22.2	5.000	139.7	1	350

VG Series Black Vinyl PVC Flat Rectangular

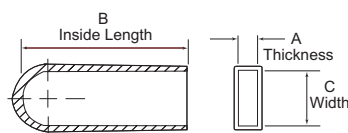

Features:

- Ideal for capping bar stock for general protection
- Flexible material can stretch onto slightly larger dimensions for a snug fit without tearing, splitting or shredding
- Special order colors and textured materials available

Item No.	A		C		B		Pack Qty.	Bulk Pack Qty.
	In	mm	In	mm	In	mm		
VG12505004375A	0.125	3.2	0.500	12.7	4.375	111.1	1	1500
VG12507504375A	0.125	3.2	0.750	19.1	4.375	111.1	1	600
VG12510004375A	0.125	3.2	1.000	25.4	4.375	111.1	1	250
VG25007504250A	0.250	6.4	0.750	19.1	4.250	108.0	1	800
VG25010004375B	0.250	6.4	1.000	25.4	4.375	111.1	1	400
VG25012504500A	0.250	6.4	1.250	31.8	4.500	114.3	1	250



**Black Vinyl  
Round or Rectangle  
Inch**



Grip replacements for worn grips on hand trucks, punch presses, tools and other equipment. Grips are molded of strong rigid black vinyl. They fit standard bar sizes and have a 1/4" hole opposite the open end, except where noted otherwise. All grips for 1" bar diameter will work with 3/4" I.P.S. pipe size.

Item No.	Style	Lgth.	For Bar Dia.	Pack Qty.	Bulk Pack Qty.	Item No.	Style	Lgth.	For Bar Dia.	Pack Qty.	Bulk Pack Qty.
GRIP1200A	A	4 1/16	3/4	1	100	GRIP0200A	G	5 1/16	7/8	1	125
GRIP1300A	A	4 3/4	7/8	1	100	GRIP0100A	G	5 1/16	1	1	100
GP-1R	A	4 1/2	1	1	50	GP-213	G	5/4	1 1/8	1	50
GP-118R	A	4 1/16	1 1/8	1	50	GP-214	G	5/4	1 1/4	1	50
GP-114R	A	4 1/16	1 1/4	1	50	GP-206	H	5/8	3/4	1	50
GP-34F	B	4 1/16	3/4	1	50	GP-207	H	5/8	7/8	1	50
GRIP0500A	B	3 3/8	7/8	1	200	GP-208	H	5/8	1	1	50
GRIP0600A	B	4 3/8	7/8	1	125	GP-209	I	4 3/4	7/8	1	50
GP-1F	B	4 9/16	1	1	50	GP-210	I	4 3/4	1	1	50
GP-118F	B	4 1/16	1 1/8	1	50	GP-12D	J	4 9/16	1/2	1	50
GP-114F	B	4 1/16	1 1/4	1	50	GP-58D	J	4 9/16	5/8	1	50
GP-4*	C	4 9/16	7/8	1	50	GP-34D	J	4 9/16	3/4	1	50
GP-5*	D	4 9/16	7/8	1	50	GRIP0700A	J	4 9/16	7/8	1	125
GP-51*	D	4 9/16	1	1	50	GRIP0800A	J	4 9/16	1	1	100
GP-8	E	4 1/2	7/8	1	50	GP-18FB	K	4 3/4	1/8 x 1	1	50
GRIP0300A	F	4 1/4	7/8	1	125	GP-316FB	K	4 3/4	3/16 x 1	1	50
GRIP0400A	F	4 1/2	1	1	125	GP-14FB	K	4 3/4	1/4 x 1	1	50
GP-211	G	4 1/8	1 1/2	1	50	GRIP1000A	L	4 5/16	1	1	125
GP-212	G	4 1/8	5/8	1	50	GRIP0900A	L	4 5/16	1 1/4	1	125
GP-203	G	5 1/16	3/4	1	50						

\*No opposite end hole

**Black Closed Cell Foam Rubber  
Soffoam  
Inch**



Sculptured




Plain

Item No.	Grip Description	Lgth.	For Bar Dia.	Pack Qty.	Bulk Pack Qty.
GP-101	Sculptured	5	3/4	1	50
GP-102	Sculptured	5	7/8	1	50
GP-103	Sculptured	5	1	1	50
GP-104	Plain	4 1/2	3/4	1	50
GP-105	Plain	4 1/2	7/8	1	50
GP-106	Plain	4 1/2	1	1	50

Made of closed cell foam rubber that can stand up to the duress of the most demanding industrial or consumer applications. The soffoam rubber material provides comfort and reduces hand fatigue especially when vibration is a factor. Excellent weathering capabilities for outdoor use. Black color.

**Black Rubber  
Round  
Inch**

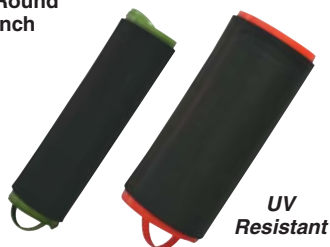

UV Resistant

These easy-to-install handle grips provide a simple, affordable and ergonomic solution for a multitude of uses. The non-slip grip provides better control and safety, while the ergonomic design reduces muscle fatigue. Can be installed on a variety of cylindrical and semi-cylindrical objects such as:

- Screwdrivers
- Hammers
- Wrenches
- Ratchets
- Levers
- Flashlights
- Shovels
- Brooms
- Rakes
- Axes
- Sledges
- Wheelbarrows

Item No.	Length	For Bar Dia.	Pack Qty.	Bulk Pack Qty.
GP-500	7	.63 to 1.3	1	50
GP-501	7	.76 to 1.6	1	50
GP-502	7	.98 to 2.2	1	50

**Note:** The colored coil shown in the photo is discarded after the grip has been installed.