


10. 外形图/Outside View

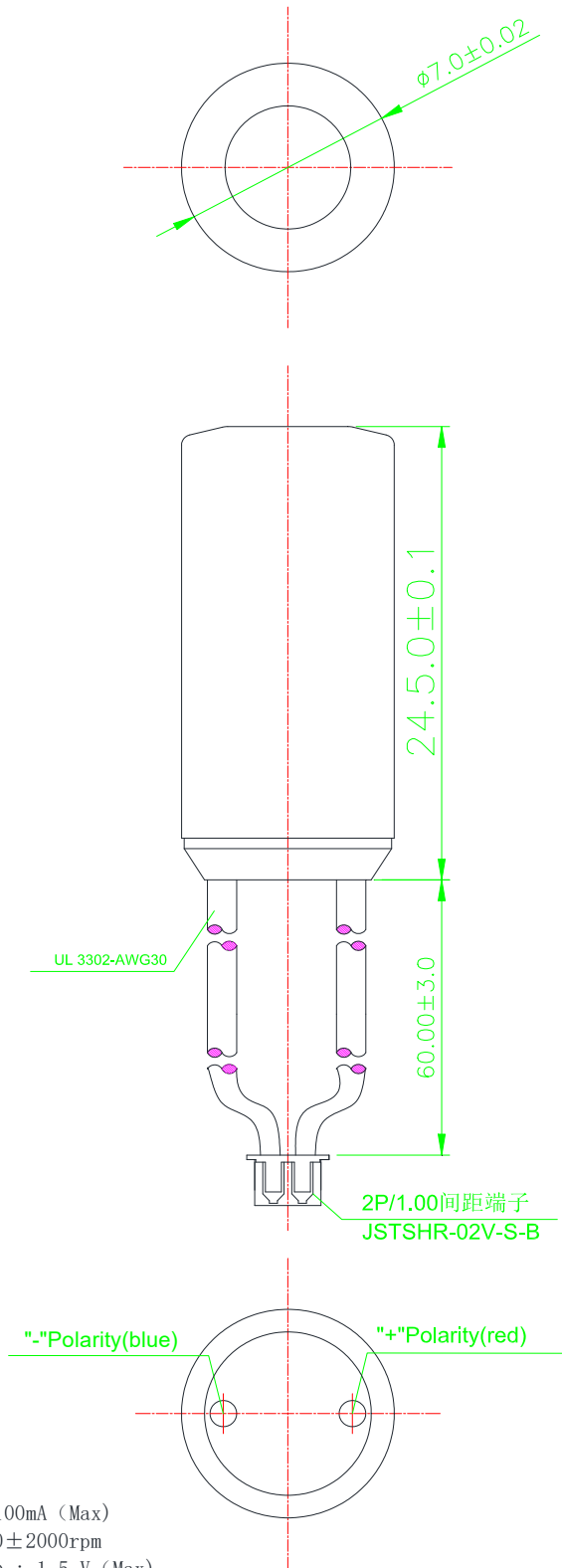

Technical requirements:

1. Rated voltage: 3.7 V
2. Rated current: 100mA (Max)
3. Rated Speed: 15000 ± 2000 rpm
4. Started voltage: 1.5 V (Max)
5. Terminal resistant: $18 \pm 15\% \Omega$
6. Rotation direction: CW/CCW

硬度	投影角 第一角	未注公差 $\pm 0.05 / \pm 0.5$	材料	比例 10/1	日期 2017/07/25
设计	审核	批准	名称	VIBRATION MOTOR	
JIE YI ELECTRONICS LIMITED			型号	JYZ0612WP-JST001	
			图号		