
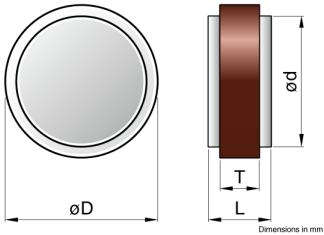


TDK item description	60739ZT172K4AA
Applications	For Power Circuit Breakers
Feature	SF6 Gas Non-InsulatedSF6 Gas (Non-insulation Type)
Series	GA
Status	 Production (Not Recommended for New Design)
Brand	TDK



Size	
D	40.00mm +0.00,-1.50mm
L	16.00mm \pm 0.50mm
T	10.00mm \pm 0.50mm
d	35.00mm \pm 0.50mm

Electrical Characteristics	
Capacitance	1.7nF \pm 10%
Rated Voltage	10kVAC
Withstanding Voltage (Nom.)	20kVAC
AC Corona Starting Voltage [3pC] (Min.)	10kVAC
Temperature Characteristic	Z5T(+22,-33%)
Dissipation Factor (Max.)	0.2%
Insulation Resistance (Min.)	10000M Ω

Other	
Operating Temperature Range	-30 to 85°C
Storage Temperature Range	-30 to 85°C
Packing	Box

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.