


DS15W350C1542D010-3001

Constant Current

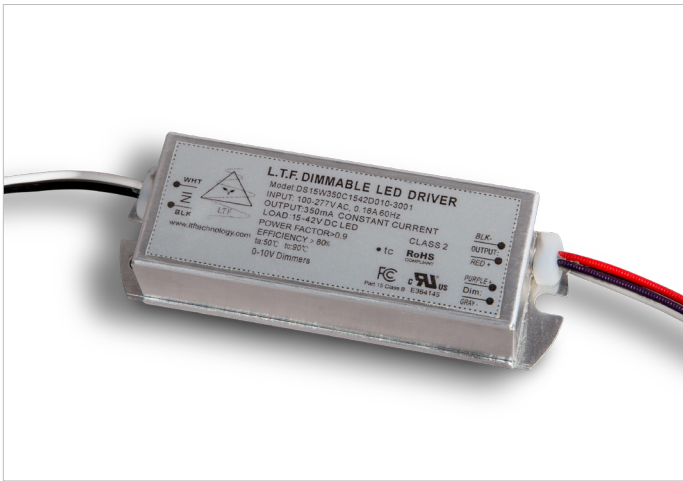

Efficiency	>80%
Power Factor	>0.90
Case TC	90°C Max.
Protection	Input / Output
Storage	-30°C / +90°C
Humidity	95% RH Max.
IP Rating	IP60
Class	Class 2 Power Supply
Dimming	0-10V only
Output Voltage or Constant Current	350mA



- Fully dimmable with only 0-10V dimmers
- Universal input 120V - 277V AC 50/60Hz
- Smooth, flicker free dimming 100% - 0.1%
- Title 24 compliant, AAA rating
- Class 2 power supply
- Isolated output power per NEC and UL safety requirements

FEATURES

- UL & ETL recognized/listed, meets UL 8750, 1310 requirements
- Auto-reset; short circuit, overload and thermal protection
- Low profile, small form factor, junction box mountable
- Efficient, high power factor >0.95


MODEL KEY

(L)	DS	96W	24V	BR1	UD	(REO)	-3002
UL Listed (Option)	Input Voltage DS = 120-277VAC DA = 120VAC DE = 277VAC DU = 220-240VAC	Wattage	24V DC Constant Voltage	Case Form Factor	UniDriver Series Tri-Mode Dimmable	Remote Enclosure RE = Indoor REO = Outdoor (Option)	Manufacturer Code

MODEL SPECIFICATIONS

Constant Current					
Model Number	Input Voltage	Wattage	Output Voltage	Output Current	Available Form Factor
DS15W350C1542D010-3001	120 - 277V AC 0.13A, 50/60Hz	15W	15V - 34VDC	350mA	T11

DIMMING CURVES

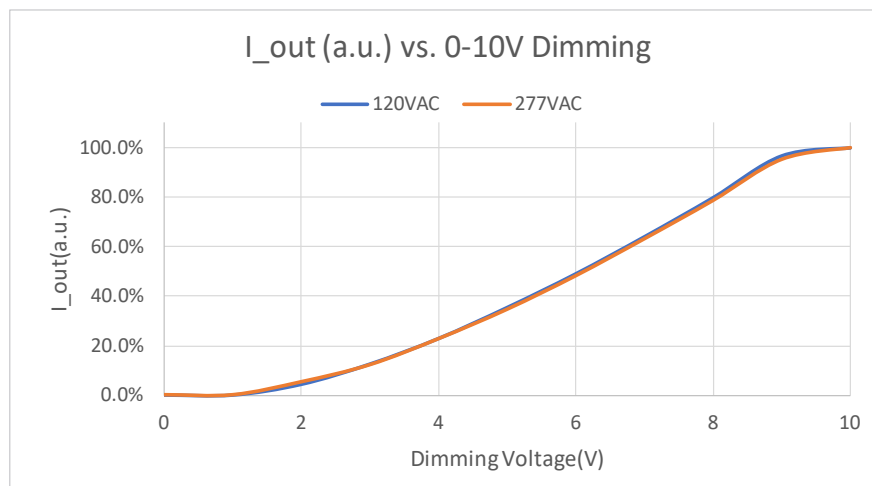

MECHANICAL SPECS

FORM FACTOR	DIMENSIONS
T11	95 (77) x 31 x 21mm

