

3U Rack Mount Cooling Unit with 3 UL Listed Fans,
110v, with NEMA 5-15P (US) Plug, Cord Length 2M



LC-3FRM3U-110V

Features

- Lighted ON/OFF Rocker Switch
- Quiet function
- Easy rack-mounting to standard 19" racks and cabinets
- 3 fans in an efficient 3U space

Applications

- 19 Inch Cabinet

Description

The L-com LC-3FRM3U-110V 3U fan unit with 3 UL listed fans conveniently mounts on standard 19-inch racks and cabinets to increase air flow, helping to prevent overheating and enhancing equipment performance. This fan unit operates quietly, with a maximum noise level of 43db-A to 47db-A. The 3U fan unit is constructed of high-quality steel with a powder-coated finish.

Even inside an equipment filled rack or cabinet, the lighted on/off rocker switch is easy to see and operate. This EIA/ECA compliant 3U fan unit comes fully assembled for a fast and simple installation. The L-com LC-3FRM3U-110V fan panel has dimensions of 1.5 inches L x 19 inches W x 5.25 inches H and requires an input voltage of 110 volts at 50/60 Hz. Our fan unit comes with a NEMA 5-15P plug and a 2-meter cord.

L-com has one of the largest in-stock selections of 3U fan panels with 3 UL-listed fans, with same-day shipment for domestic and international orders. Make your online purchase right now to take advantage of our same-day shipping. Our expert technical support and knowledgeable sales team can assist you in obtaining the 3U fan unit that meets your needs.

Configuration

Enclosure Color	Black
Number of Fans	3
Mount Option	Rack Mount

Electrical Specifications

Description	Minimum	Typical	Maximum	Units
Voltage		110		VAC
RPM		2650		

Mechanical Specifications

Size		
Length	1.5 in	[38.1 mm]
Width	19 in	[482.6 mm]
Height	5.25 in	[133.35 mm]
Weight	5.5 lbs	[2.49 kg]

3U Rack Mount Cooling Unit with 3 UL Listed Fans,
110v, with NEMA 5-15P (US) Plug, Cord Length 2M



LC-3FRM3U-110V


3U Rack Mount Cooling Unit with 3 UL Listed Fans, 110v, with NEMA 5-15P (US) Plug, Cord Length 2M from L-com has same day shipment for domestic and International orders. Our portfolio includes coaxial cable assemblies, connectors, adapters and custom products as well as lightning and surge protectors, NEMA rated enclosures, and an RF product line which includes antennas, amplifiers, passive, and active components.

URL: <https://www.l-com.com/3u-rack-mount-cooling-unit-3-ul-listed-fans-110v-nema-5-15p-us-plug-cord-2m-lc-3frm3u-110v-p.aspx>

The information contained within this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part in order to implement improvements. L-com reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal. L-com does not make any representation or warranty regarding the suitability of the part described herein for any particular purpose, and L-com does not assume liability arising out of the use of any part or document.

3U Rack Mount Cooling Unit with 3 UL Listed Fans, 110v, with NEMA 5-15P (US) Plug, Cord Length 2M CAD Drawing

3U Rack Mount Cooling Unit with 3 UL Listed Fans, 110v, with NEMA 5-15P (US) Plug, Cord Length 2M

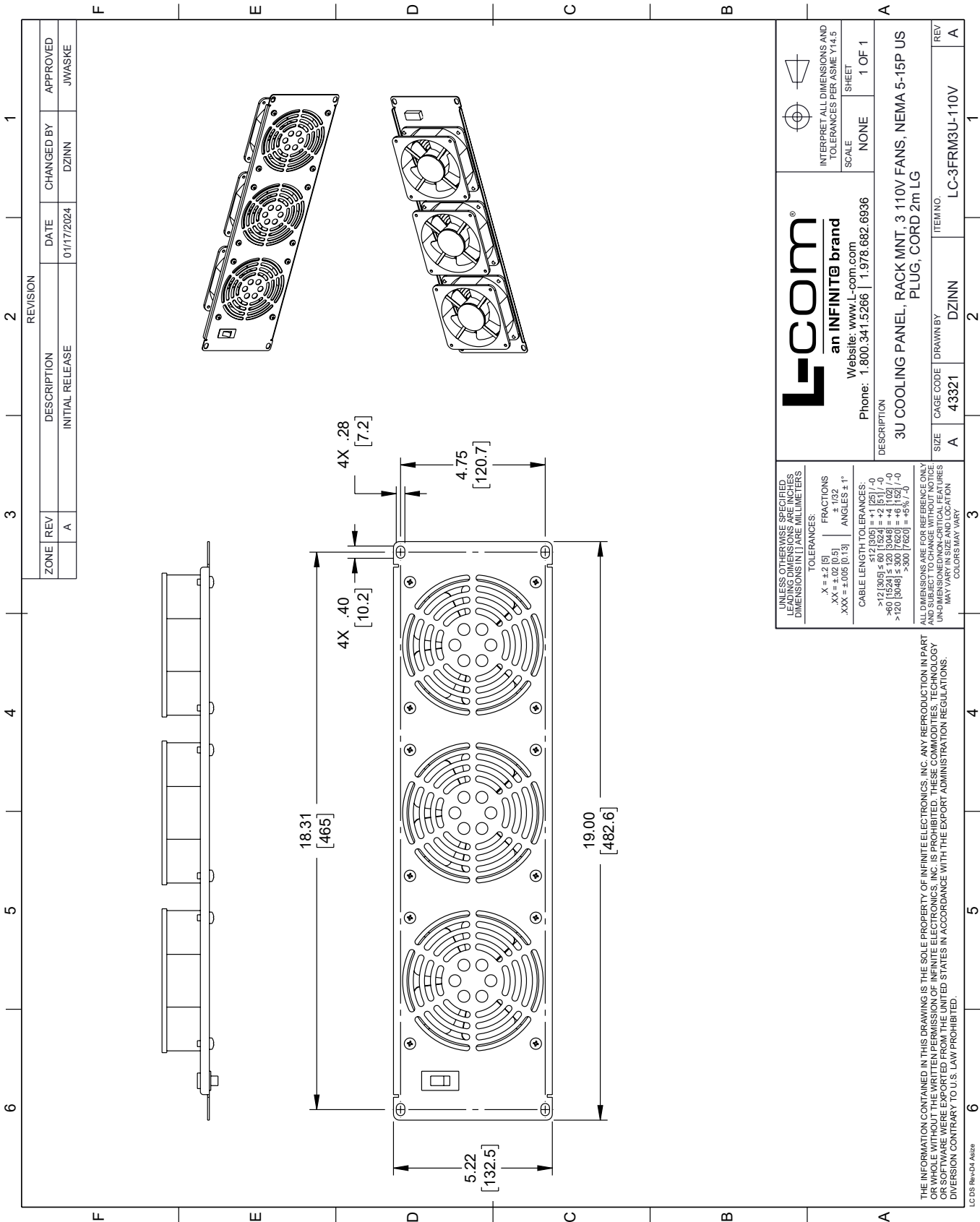

L-com® an INFINITE brand Website: www.L-com.com Phone: 1.800.341.5266 1.978.682.6936		INTERPRET ALL DIMENSIONS AND TOLERANCES PER ASME Y14.5 SCALE: NONE SHEET: 1 OF 1	
UNLESS OTHERWISE SPECIFIED, LEADING DIMENSIONS ARE IN INCHES. DIMENSIONS IN [] ARE IN MILLIMETERS. TOLERANCES: X = ±.2 [5] .XX = ±.02 [0.5] .XXX = ±.005 [0.13] FRACTIONS: ± 1/32 ANGLES: ± 1° CABLE LENGTH TOLERANCES: >12 [305] ≤ 60 [1524] = ±.125 [-0] >60 [1524] ≤ 120 [3048] = ±.125 [-0] >120 [3048] ≤ 300 [7620] = ±.125 [-0] ALL DIMENSIONS ARE FOR REFERENCE ONLY. UNDIMENSIONED/NON-CRITICAL FEATURES MAY VARY IN SIZE AND LOCATION. COLORS MAY VARY.		DESCRIPTION 3U COOLING PANEL, RACK MNT., 3 110V FANS, NEMA 5-15P US PLUG, CORD 2m LG	
SIZE	CAGE CODE	DRAWN BY	ITEM NO.
A	43321	DZINN	LC-3FRM3U-110V
REV	A		