

# HC-STA-B24-HLFS-1STP16-EL/... - Housing



1373263

<https://www.phoenixcontact.com/pc/products/1373263>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B24, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, 1x Pg16, height: 60 mm, cable gland: none, with choice of powder coating color

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1373263                        |
| Packing unit                         | 1 pc                           |
| Minimum order quantity               | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Product key                          | AF7APB                         |
| Weight per piece (including packing) | 245.8 g                        |
| Weight per piece (excluding packing) | 245.8 g                        |
| Customs tariff number                | 85389099                       |
| Country of origin                    | PL                             |

# HC-STA-B24-HLFS-1STP16-EL/... - Housing



1373263

<https://www.phoenixcontact.com/pc/products/1373263>

## Technical data

 
### Notes

|         |                                                                              |
|---------|------------------------------------------------------------------------------|
| General | powder-coated and color version of item 1412785 HC-STA-B24-HLFS-1STP16-EL-AL |
| General | for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M                     |

### Product properties

|                              |                            |
|------------------------------|----------------------------|
| Product type                 | Housing with locking latch |
| Housing type                 | Sleeve housing             |
| Application                  | Standard                   |
| Design                       | B24                        |
| Type of locking              | for single locking latch   |
| No. of cable outlets         | 1                          |
| Type of the screw connection | 1x Pg16                    |
| Cable outlet                 | lateral                    |

### Dimensions

|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 44 mm                                                                                |
| Height              | 60 mm                                                                                |
| Length              | 120 mm                                                                               |

### Material specifications

|                          |                                         |
|--------------------------|-----------------------------------------|
| Color                    | black (RAL 9005)                        |
| Housing material         | Die-cast aluminum, salt water resistant |
| Housing surface material | uncoated                                |

### Environmental and real-life conditions

#### Ambient conditions


|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP66              |
|                                 | IP67              |
| Enclosure rating (NEMA)         | 4 (UL 50e)        |
|                                 | 4X (UL 50e)       |
|                                 | 12 (UL 50e)       |
| Impact strength                 | IK08              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

## Drawings

### Application drawing

|                                                                                     |                      |                                                                                     |                      |
|-------------------------------------------------------------------------------------|----------------------|-------------------------------------------------------------------------------------|----------------------|
|    | <b>YE – RAL 1021</b> |    | <b>WH – RAL 9016</b> |
|    | <b>RD – RAL 3020</b> |    | <b>VT – RAL 4004</b> |
|    | <b>GY – RAL 7045</b> |    | <b>GN – RAL 6005</b> |
|   | <b>PL – RAL 4006</b> |   | <b>BN – RAL 8017</b> |
|  | <b>BK – RAL 9005</b> |  | <b>OG – RAL 2004</b> |
|  | <b>BU – RAL 5005</b> |                                                                                     |                      |

### Dimensional drawing

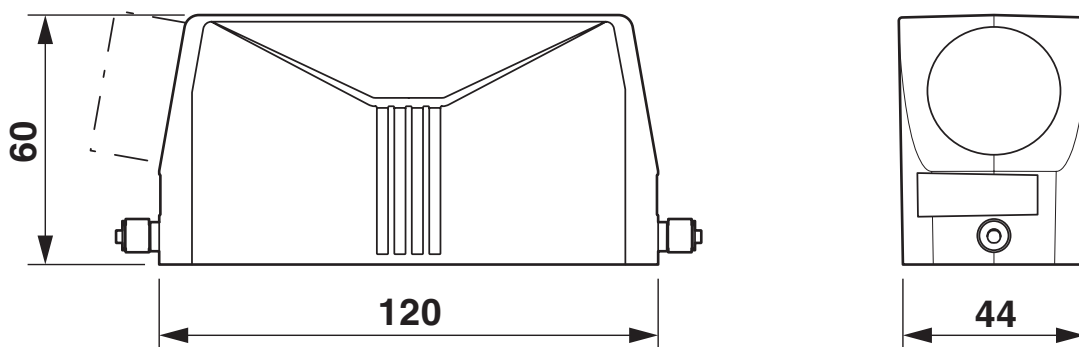

# HC-STA-B24-HLFS-1STP16-EL/... - Housing



1373263

<https://www.phoenixcontact.com/pc/products/1373263>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/pc/products/1373263>



**cUL Recognized**  
Approval ID: E255026



**UL Recognized**  
Approval ID: E255026

**cULus Recognized**

# HC-STA-B24-HLFS-1STP16-EL/... - Housing

1373263

<https://www.phoenixcontact.com/pc/products/1373263>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27440202 |
| ECLASS-12.0 | 27440202 |
| ECLASS-13.0 | 27440202 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000437 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

1373263

<https://www.phoenixcontact.com/pc/products/1373263>

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachmarktstraße 8  
D-32825 Blomberg  
+49 (0) 5235-3 00  
[info@phoenixcontact.com](mailto:info@phoenixcontact.com)