



SIGN	DATE	DESCRIPTION	APPROVER
△			
△			
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!			

Material

- Item (a) Clamp: Brass(CuZn)Ni plated
- Item (b) Terminal screw: Steel Zinc plating "-" slot type
- Item (c) Female contact: PhBz Tin plated
- Item (d) Terminal (up body): Thermoplastic (UL94V-0)
- Item (e) Terminal (down body): Thermoplastic (UL94V-0)

Electrical cULus

- Voltage rating: 300VAC
- Current rating: 20A
- Wire range:
- Solid wire(AWG): 12-24
- Stranded wire(AWG): 12-24/(2×AWG14)
- Torque: 4.0 Lb-In
- Screw: M3
- Wire strip length: 6-7mm
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +115°C
- Safety approval: cULus

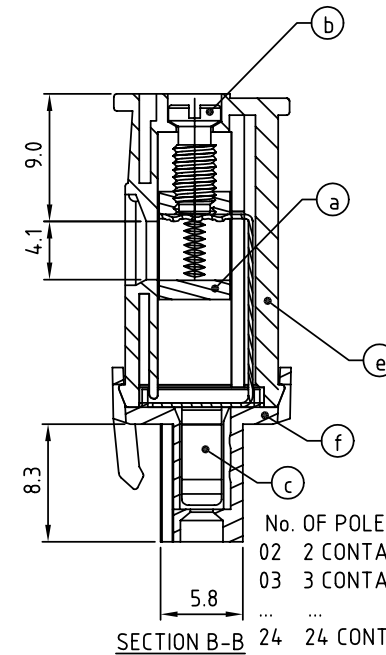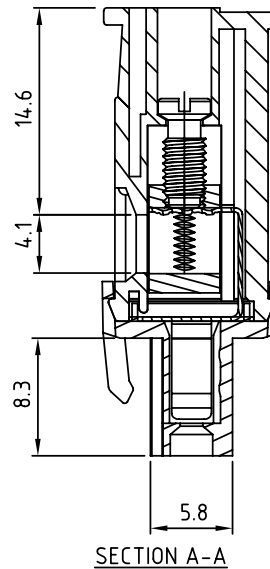

EY xx 51 x A xxx G

No. OF POLES
02 2 CONTACTS
03 3 CONTACTS
...
24 24 CONTACTS

Color
0 Black (RAL9005)
2 Red (RAL3001/D)
3 Orange(RAL2011/P)
4 Yellow(RAL1018/A)
5 Green(RAL6018/T)
6 Blue (RAL5015/A)
8 Grey(RAL7035/D)

G: Pb<40000ppm
0000: "@" Logo (Standard)
000A: "ANYTEK" Mark
Any special item by customer request, please contact sales department.

ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE		EY-5.08mm Series (W/latching hooks on the wire entry side)					
PART NO.		EYxx51xAxxxxG			DWG NO. 8EY0001		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.		Tolerance	
	Marvin	Marvin	Marvin			UNIT: mm	X. ±0.50
	2007.10.05	2007.10.05	2007.10.05			SCALE: NONE	X.X ±0.30
						REV.: B	X.XX ±0.10
SHEET: 01/01				REV.: B			

