


PANEL CUT-OUT

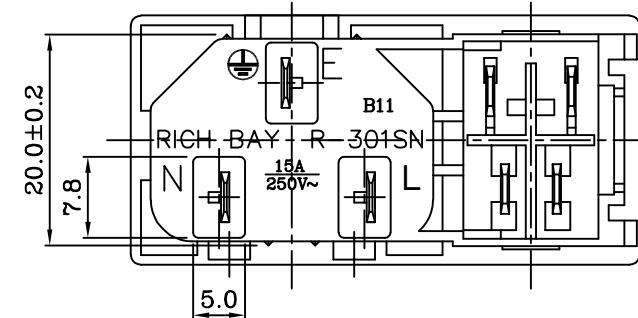

SPECIFICATION (SWITCH) :

- 1.RATING : 10A 125V/250V~T105(UL CUL).  
6(2)A 250V~ 1E4  $\mu$  (VDE, SEMKO, NEMKO, DEMKO, FIMKO.)
- 2.CONTACT RESISTANCE : 30m  $\Omega$  Max.
- 3.INSULATION RESISTANCE : DC 500V 100M $\Omega$  Min.
- 4.WITHSTAND VOLTAGE : AC 1000V 1 Minute, 5mA.
- 5.ELECTRICAL LIFE : 10,000 Cycles At Full Load.

SPECIFICATION (INLET) :

1. INSULATION RESISTANCE : Over 100M $\Omega$  at 500V DC.
2. DIELECTRIC STRENGTH : 2000V AC 1 Minute.
3. BOBY MATERIAL : Black Glass-Fiber Thermoplastic.UL 94V-0.



Rating:AC 15A 250V	
Mark	Safety Regulation
cULus	cULus
Rating:AC 10A 250V	
Mark	Safety Regulation
CCC	CCC
TUV	TUV