

Contact insert - HC-HV 10-ESTS - 1773394

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)


HEAVYCON male insert, for 690 V(III/3), with 10 N/O contacts and 2 switching contacts, screw connection



The illustration shows a combination of versions HC-HV -10-EBUC, -10-EBUS, -10-ESTC and -10-ESTS



Key commercial data

Packing unit	1 pc
GTIN	 4 017918 037673
Weight per Piece (excluding packing)	111.62 GRM
Custom tariff number	85366990
Country of origin	Germany

Technical data

General

Note	For housings HC ADVANCE-B24, H-HV 10/16
Connection method	Screw connection
Tightening torque	0.5 Nm
Pollution degree	3
Surge voltage category	III
Constructional and testing regulations	DIN VDE 0627/86
	DIN VDE 0110/02.79
	DIN VDE 0110-1/04.97
	IEC 60664-1, DIN IEC 60512
	IEC 60352
Number of positions	10+2+PE

Contact insert - HC-HV 10-ESTS - 1773394

Technical data

General

Insertion/withdrawal cycles	≥ 500
Design	HV10
Conductor cross section	0.5 mm ² ... 2.5 mm ²
Connection cross section AWG	20 ... 14
Stripping length of the individual wire	7 mm (N/O contacts)
	7 mm (control contacts)

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (including heating up of contacts)
---------------------------------	--

Material data

Inflammability class according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Ag
Contact carrier material	PA

Electrical characteristics

Rated voltage (III/3)	Power 400 V (Conductor-PE)
	(250 V control contacts)
Rated surge voltage	Power 690 V (Conductor-Conductor)
	6 kV (N/O contacts)
	4 kV (control contacts)
Rated current	16 A

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 2.0	EC000438
ETIM 3.0	EC000438
ETIM 4.0	EC000438

Contact insert - HC-HV 10-ESTS - 1773394

Classifications

ETIM

ETIM 5.0	EC000438
----------	----------

UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Approvals

Approvals

Approvals

GOST

Ex Approvals

Approvals submitted

Approval details

GOST

Accessories

Accessories

Mounting material

PE multiplier - HC-B-3PE - 1644326




PE multiplier, for three PE connections, for HC-B (besides HC-B..E..ZZ) / HC-BB / HC-DD / HC-D40 / HC-D64 contact inserts

Contact insert - HC-HV 10-ESTS - 1773394

Accessories

Drawings


Schematic diagram

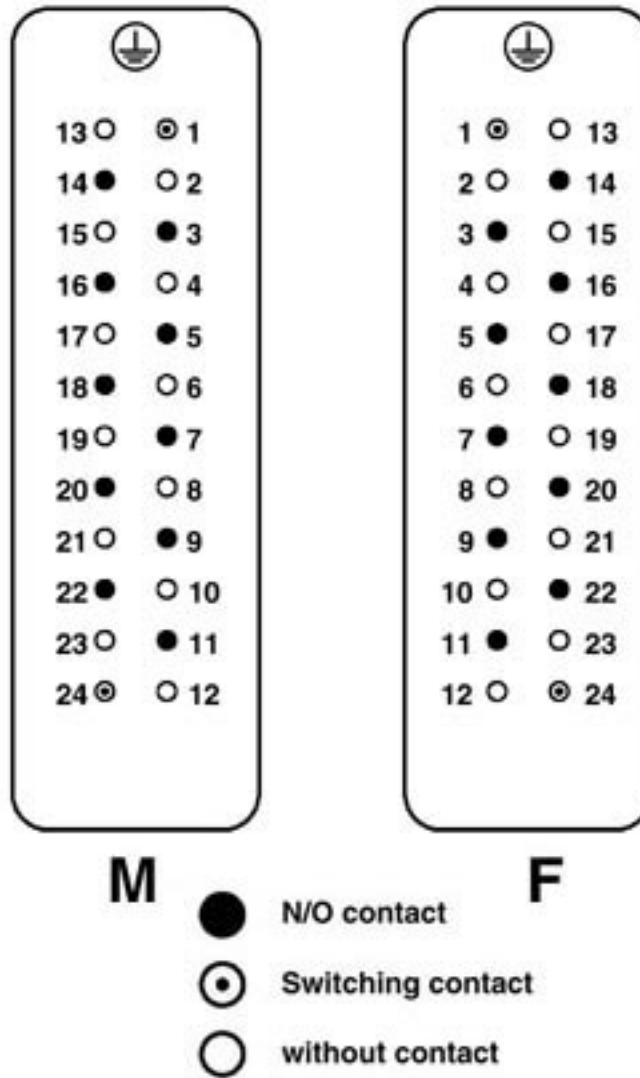

View termination side

Contact insert - HC-HV 10-ESTS - 1773394

Diagram

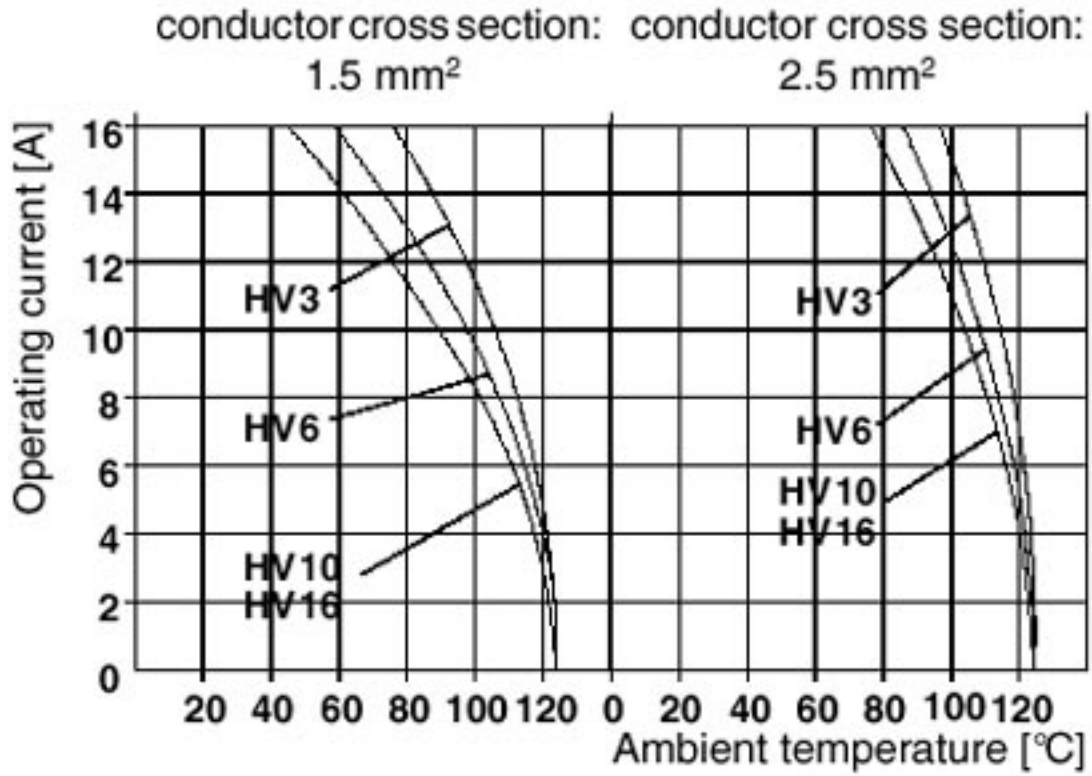

Contact insert - HC-HV 10-ESTS - 1773394

