





Varicon®

Series 5208 – Contact Strip

Perpendicular Cards – Pad Spacing .200"

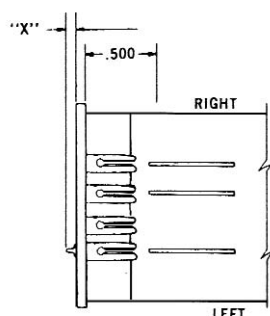

Contact	"X"
113	.060
114	.060
115	.060
121	.281
122	.250

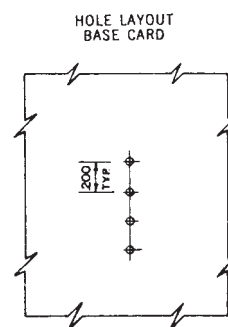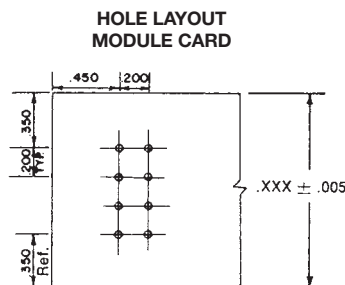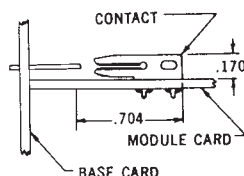

All hole diameters are $+.000$
 $-.004$
 Hole locations to be within
 .006" diameter of true location

TECHNICAL SPECIFICATIONS

Contacts:

Supplied on disposable plastic carrier strips.

Current Rating:

8 amperes

Contact Resistance:

0.006 Ohm, maximum

Contact Material and Plating:

Phosphor Bronze

Gold, 10 microinches minimum,
 over nickel, 50 to 100 microinches

Insertion/Withdrawal Force:

2 to 16 ounces per contact

ORDERING CODE – BASE CARD CONTACTS

02

000

000

3

200

000

Number of Contacts
 on Strip
 1 to 63

Contact Style

113		1/16" card
114		3/32" card
121		3/32" card
122		1/8" card

- Card Guides: See top drawing for appropriate part number
- Contacts

ORDERING CODE – MODULE CARD CONTACTS

02

000

000

5

200

000

Number of Contacts
 on Strip
 1 to 63

Contact Style

In-Line:		
013		1/16" card
014		3/32" card

For loose contacts, order by individual
 part numbers tabulated on page 53.