
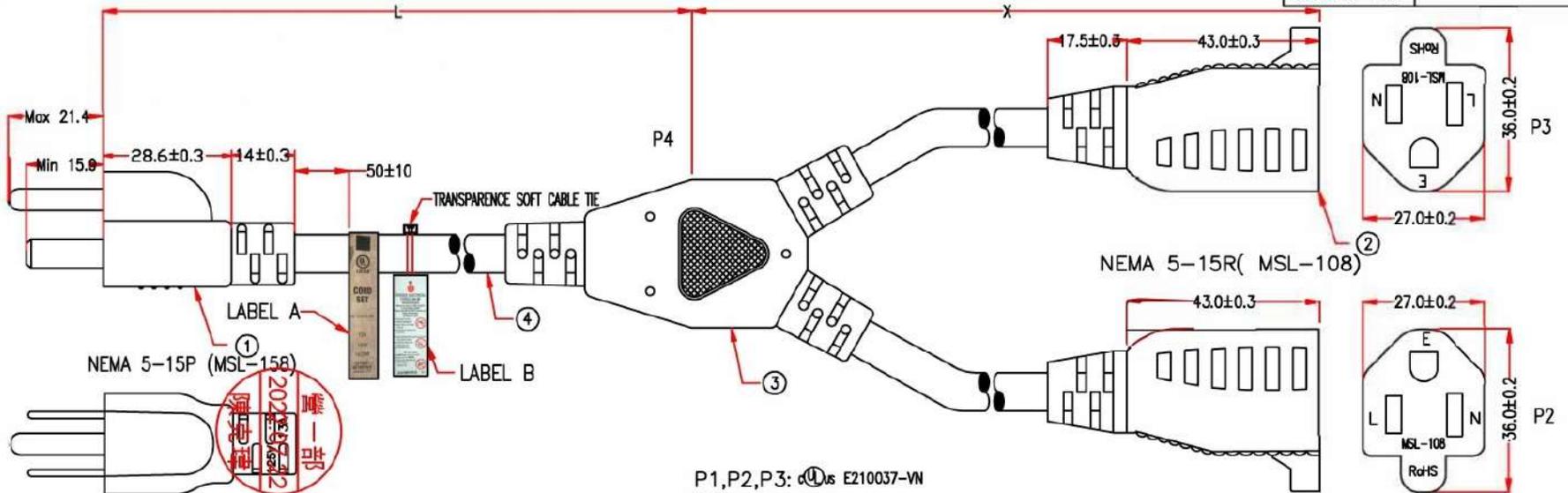


P1: M-084A

P2,P3: M-007




P4: M-008

Customer No.:

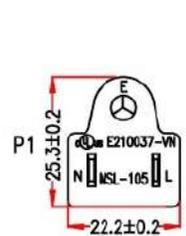


P1,P2,P3: Ⓞ E210037-VN
 P4: Ⓚ E210037

PACKING:

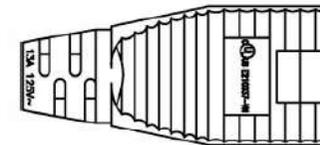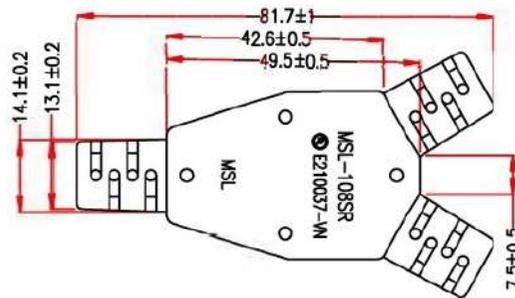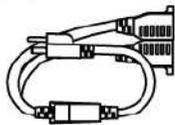

P/N	Length(L)	Length(X)
AC-21214-Y	178mm	178mm
AC-21224-Y	432mm	178mm
AC-21236-Y	737mm	178mm
AC-21272-Y	1220mm	610mm

 

LABEL A

MARKING:

(UL) SJT 3/C 16AWG(1.31MM²) VW-1 75°C 300V E204978 C(UL)
 SJT 3/C 1.31MM²(16AWG) FT2 60°C 300V E204978 MSL-VN-

110158B2F16A(FP400-00)		
P1	P2	P3
BLACK L	L	L
WHITE N	N	N
GREEN E	E	E

1 OF 2

*NOTE: ALL relevant materials are complied with RoHS directive.
 LABEL A IS "UL LABEL"
 LABEL B IS "WARNING LABEL"

APPROVED			Cable Length Unless Other Spec. Tolerances: 0 ~200mm ±10mm 201~1000mm ±20mm 1001 ~1500mm ±25mm 1501~2100mm ±30mm 2100mm↑ ±40mm
CHECKED	HU		
DESIGNER	XJW		
DRAWING	WEI		
DATE	13/JUL/22		
ITEM NO.	AC-212XX-Y	UNIT:mm	

REV.1 2022.07.13 CANCEL P1 INTERNAL MODEL

NOTE: Cable Length Unless Otherwise Spec. Tolerances: Under 6FT ±25mm; Another ±50mm

1 FT LENGTH LABEL :




LABEL B BACK

LABEL B FRONT

THE LABELED LENGTH CHANGES ACCORDING TO THE ACTUAL LENGTH

3 FT LENGTH LABEL :

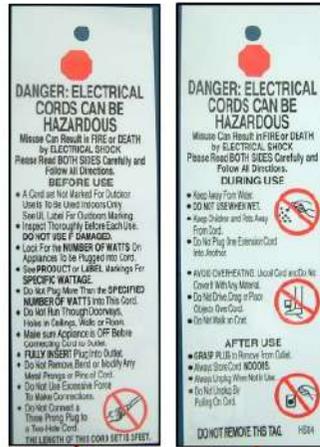

LABEL B BACK

LABEL B FRONT

≥ 6 FT LENGTH LABEL :



LABEL B BACK

LABEL B FRONT

*NOTE: ALL relevant materials are complied with RoHS directive.
THE MARKING IS CONCAVE LETTERING MOULD

4	UL SJT 16AWG*3C OD 8.5mm, JACKET BLACK, DRAWING No.EPSYT011603C-058	H5TC43-0304K09	Lmm*1PCS Xmm*2PCS	M304
3	MOLDED PVC 35P, COLOR BLACK	H1BC02-0304K09		M304
	BRACKET: YS-021	A1QC18-0767	1	M767
2	TERMINAL: 96146BS-0	A1QB17-0257	3	M257
	MOLDED PVC 45P, COLOR BLACK	H1BF01-0304K09		M304
	BRACKET: YS-016	A1QC15-0767W09	2	M767
1	TERMINAL: 98575BS-0	A1QB09-0257	2	M257
	TERMINAL: 98752BS-0	A1QB11-0257	4	M257
	MOLDED PVC 35P, COLOR BLACK	H1BC02-0304K09		M304
	TERMINAL WITH BRACKET: M87629LA-3PB	A1QC82-0257K09	1	M257

No.	DESCRIPTION		Q'TY	Supplier
APPROVED				
CHECKED	HU			
DESIGNER	XJW			
DRAWING	WEI			
DATE	12/JUL/22	ITEM NO.	AC-212XX-Y	

Cable Length Unless Other Spec.
Tolerances:

0 ~200mm	±10mm
201~1000mm	±20mm
1001 ~1500mm	±25mm
1501~2100mm	±30mm
2100mm↑	±40mm