

Float Switch Water Level Sensor



■ **FEATURE**

- Use the measure the height of Water Level
- The body part designed to be free of water
No malfunction due to slime and Foreign material
- Molded with resin, make it resistance to physical impact


■ **APPLICATIONS**

Air-Conditioner, etc.

■ **ELECTRICAL DATA**

| NO | PART | specification |
|----|-------------------------------|---------------------------|
| 1 | Operating specification | AT40 ~ AT45 (REED SWITCH) |
| 2 | Max switching power | 10W / 12V |
| 3 | Max switching voltage | 100 Vdc |
| 4 | Max switching current | 0.5A |
| 5 | Carrying current | 0.7A |
| 6 | Opperrating Temperature Range | 0℃ ~ 70℃ |

DIMENSION

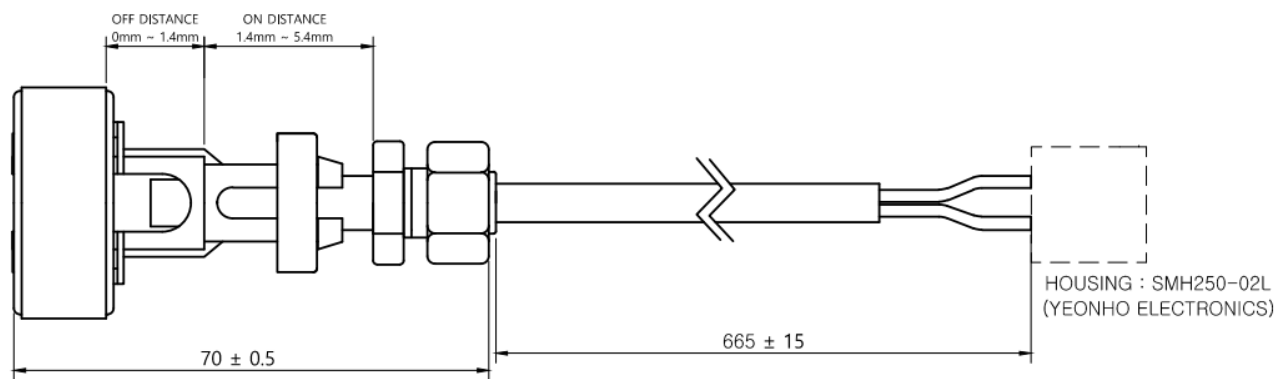

| | | |
|-------------------|----------|---------------------|
| Measured Distance | Full On | (~1.4mm) |
| | On / Off | (1.4mm ~ 5.4mm) |
| | Full Off | (~ 5.4mm or more) |

DK SENSOR CO.,LTD.

Headquarters : 45, Gasan digital 1-ro, Geumcheon-gu
Seoul, KOREA

dksensor@dksksensor.com