



Maswell Log Periodic Antenna 5G/4G 750-3800MHz

AN_GSM_101-5G

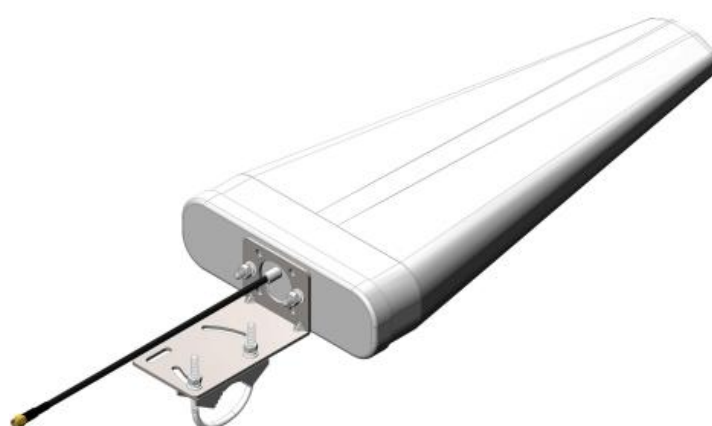

Mechanical dimension

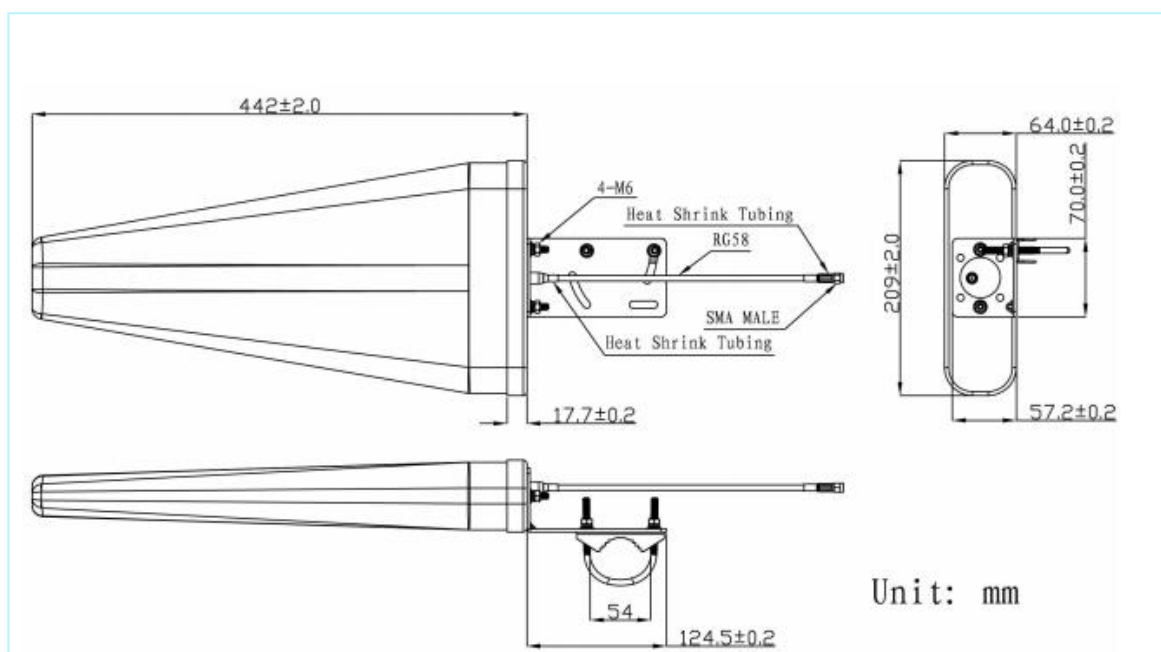

Maswell Log Periodic Antenna 5G/4G 750-3800MHz

AN_GSM_101-5G





Specifications

Item		Specifications
WIFI&GSM Antenna	Frequency Range	750~3800MHz
	Polarization	Linear
	Gain	11dBi
	V.S.W.R	<2.0
	Impedance	50Ω
Mechanical	Cable	RG58
	Connector	N/SMA or others
	Mounting Method	Screw
	Radome Material	ABS
Environmental	Operating Temperature	-40℃~+85℃
	Relative Humidity	Up to 95%
	Environmentally Friendly	ROHS Compliant

Maswell Log Periodic Antenna 5G/4G 750-3800MHz

AN_GSM_101-5G


Radiation Patterns

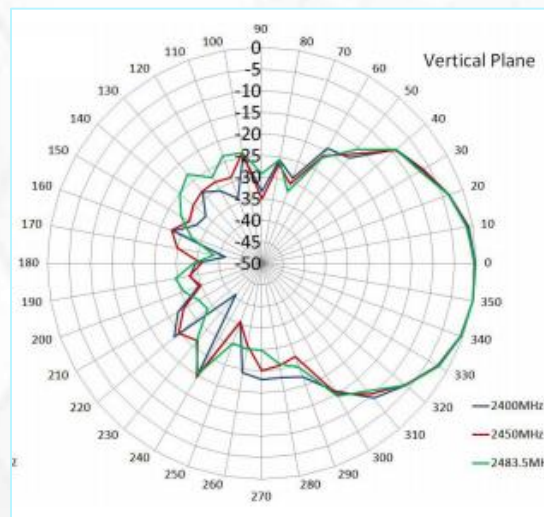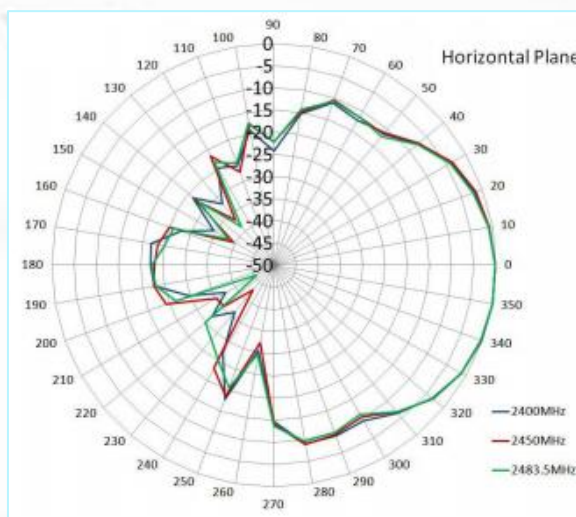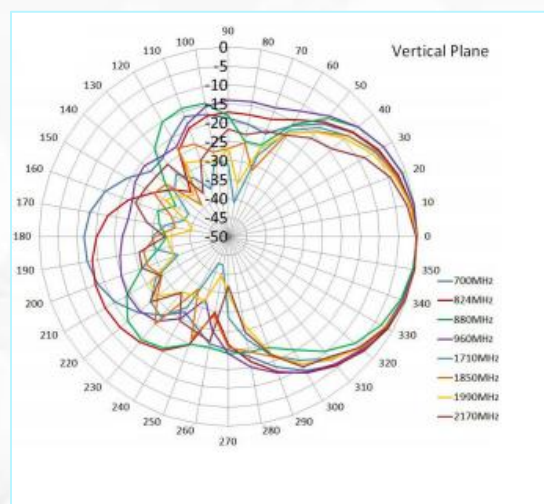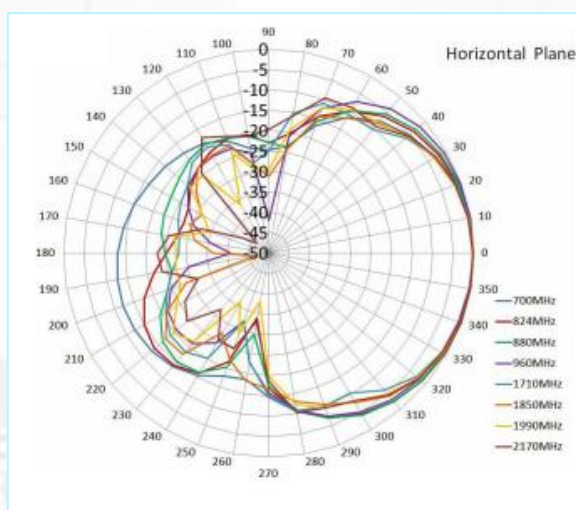

Maswell Log Periodic Antenna 5G/4G 750-3800MHz

AN_GSM_101-5G

S11 Measured Results

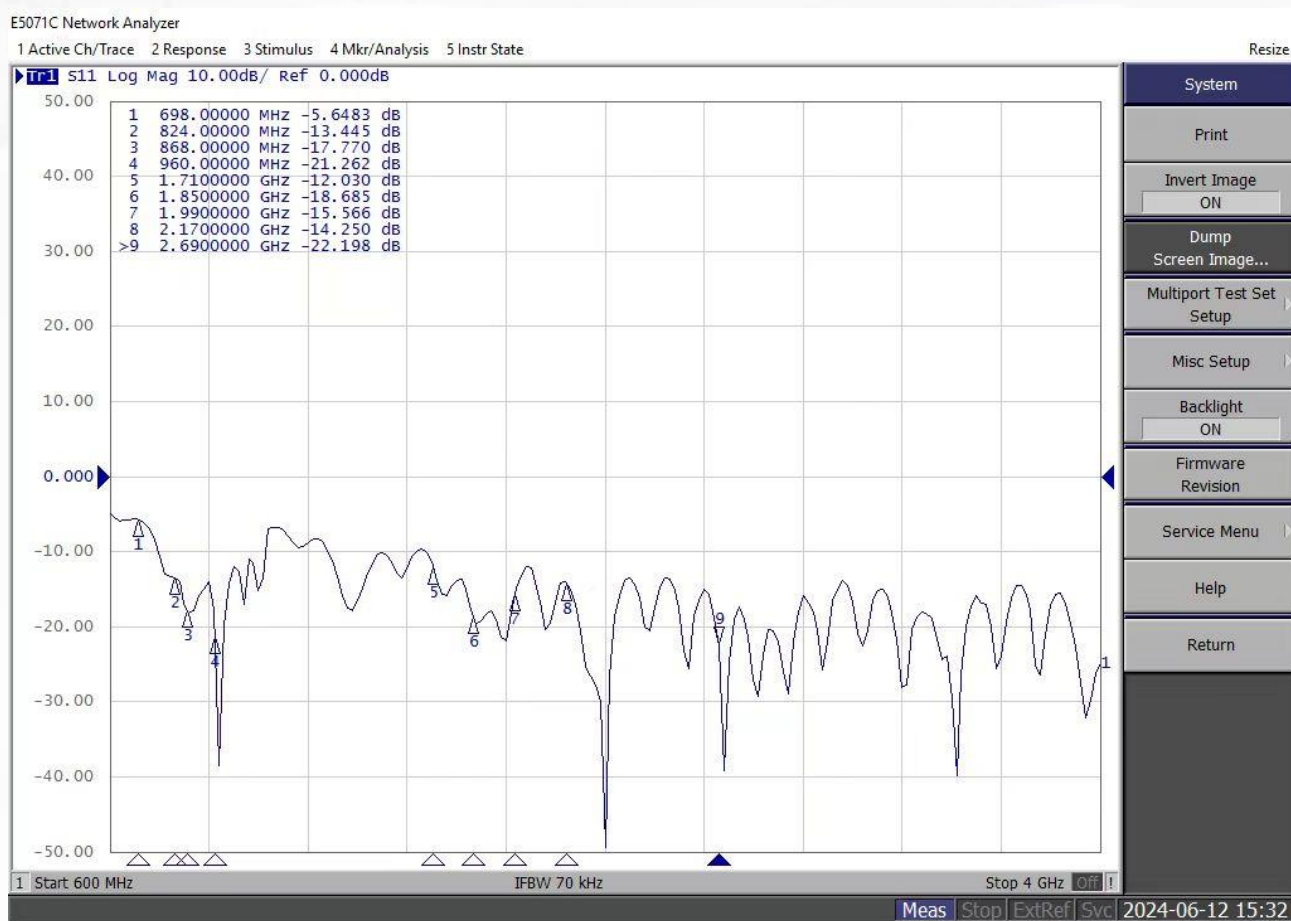

Maswell Log Periodic Antenna 5G/4G 750-3800MHz

AN_GSM_101-5G

VSWR Measured Results

