


Maswell 4G/5G Yagi Antenna 700-4000MHz

AN_GSM_102



Mechanical dimension

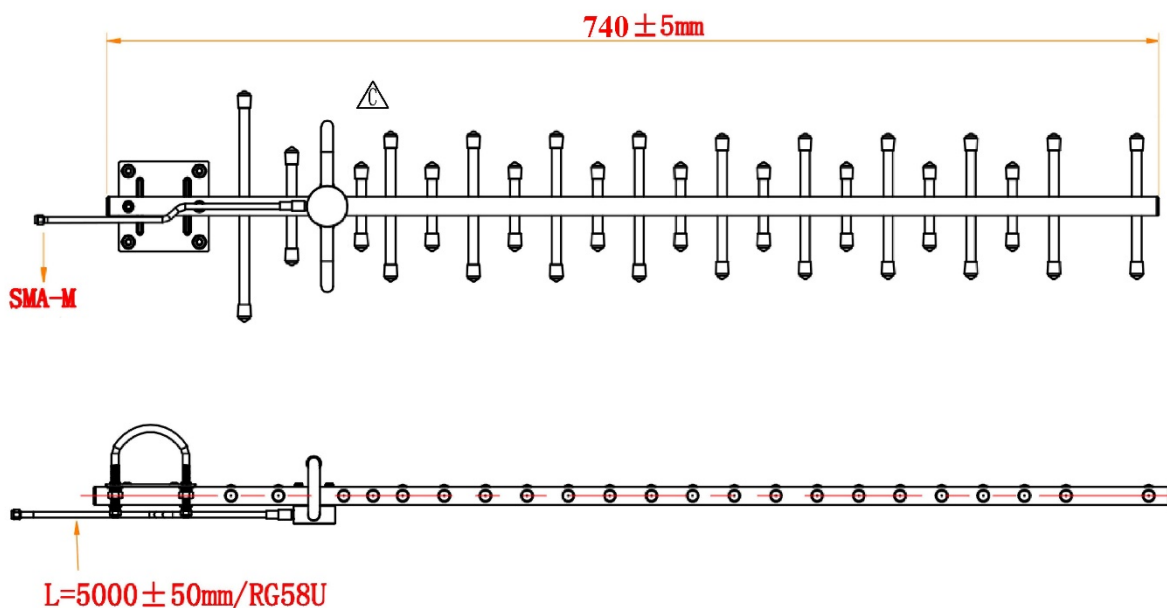

Maswell 4G/5G Yagi Antenna 700-4000MHz

AN_GSM_102


Specifications

Item		Specifications
Antenna	Frequency Range	700-4000MHz
	Bandwidth	3300MHz
	Gain	12.0dBi
	Element	16
	Beam Width	H : 48° V : 40°
	Front To Back Ratio	≥16dB
	VSWR	≤1.5
	Input Impedance	50Ω
	Polarization	Horizontal or Vertical
	Max Power	100W
Mechanical	Lightning Protection	DC Ground
	Cable Length	5m
	Connector	SMA male
	Antenna Weight	1.2KG
	Dimension	740*185*60 mm
	Clamp	U
	Pole Diameter	Φ40~Φ50
Environmental	Operating Temperature	-40°C~+60°C
	Rated Wind Velocity	60m/s
	Environmentally Friendly	ROHS Compliant

Maswell 4G/5G Yagi Antenna 700-4000MHz

AN_GSM_102

S11 Measured Results

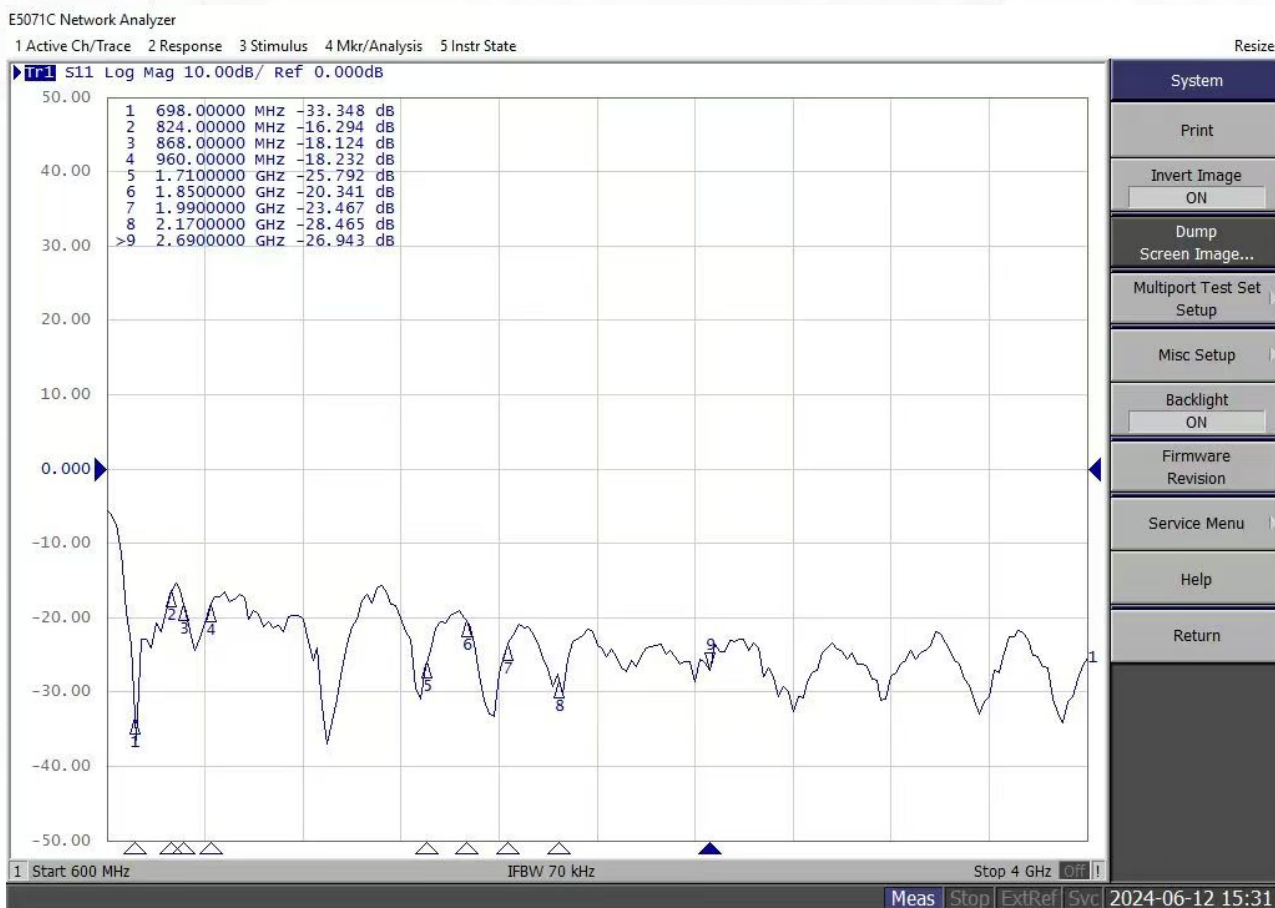

Maswell 4G/5G Yagi Antenna 700-4000MHz

AN_GSM_102

VSWR Measured Results

