


STRIP LENGTHS

RevNo	Revision Notes	Date	Checked
1	RoHS Compliant	041025	PC

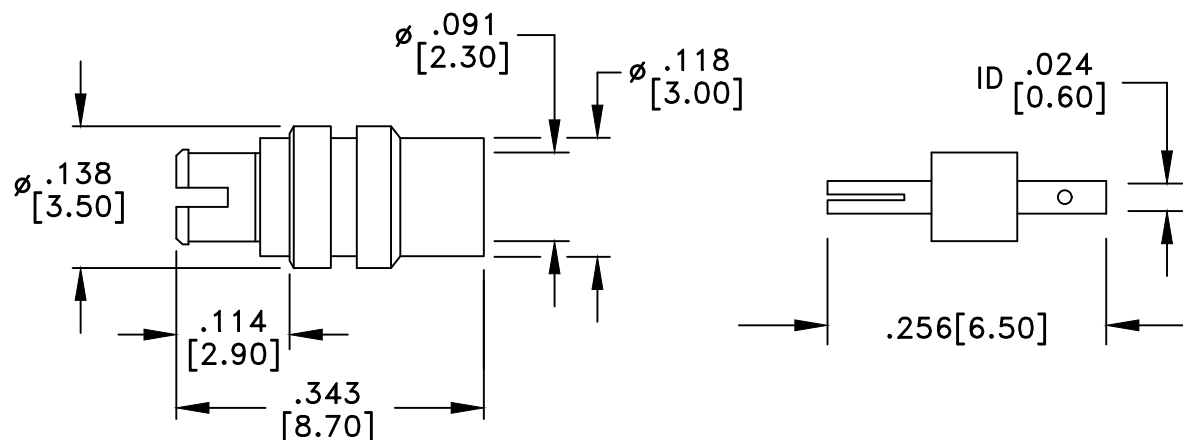

RoHS Compliant

MATERIALS

BODY	BeCu
BODY PLATING	GOLD
CONTACT	BeCu
CONTACT PLATING	GOLD
DIELECTRIC	TEFLON (PTFE)

50 Ohm IMPEDANCE
500V PEAK VOLTAGE RATING
TEMPERATURE RANGE: -55°C TO +155°C
INTERFACE DIMENSIONS SIMILAR TO MIL-C-39012

MILLIMETER WAVE TECHNOLOGIES
6501 W. FRYE ROAD, #23
CHANDLER, AZ 85226

SMPM FEMALE STRAIGHT
CABLE END
for .086" RG405

Designed by N. JAIN	Checked by S. NEUGESS	Approved by A. LEE	File name MWPM-6010-G-086	TITLE MWPM-6010-G-086
TOLERANCES DIMENSIONS IN INCHES UNLESS OTHERWISE SPECIFIED DECIMALS .XX ± .02 .XXX ± .005		ALL DIMENSIONS ON THIS DRAWING ARE FOR REFERENCE PURPOSES ONLY AND ARE SUBJECT TO CHANGE.		REV. 1 DATE 041025
ANGULAR ± .06				Scale NONE Sheet 1 of 1