

Description

PJ Splice Tape is a SR signature tape that does not need any splice clips and tools separately.

PJ-124AB ~ PJ-172AB	
Set Q'ty	250EA
Compatible Smart Feeder	Fuji/ASMPT/Universal
Set Q'ty Carrier Tape Application	24mm~72mm
Recommended SR Cutting Tools With PJ Splice Tape	Cutting Jig (SCJ-108P) Cutting Jig (SCJ-132P) Cutting Jig (CJ-172) Shift Pitch Scissor (ASPS-032) Shift Pitch Scissor (SPC-056)



“Original Manufacturer
– Made in Korea”


PJ Splice Tape

MODEL . PJ-1XXAB

General Description

PJ Splice Tape is SR HIGHTECH’s one-tape solution for carrier tape splicing. No splice clips or additional tools required — just precise and clean results.

Product Construction

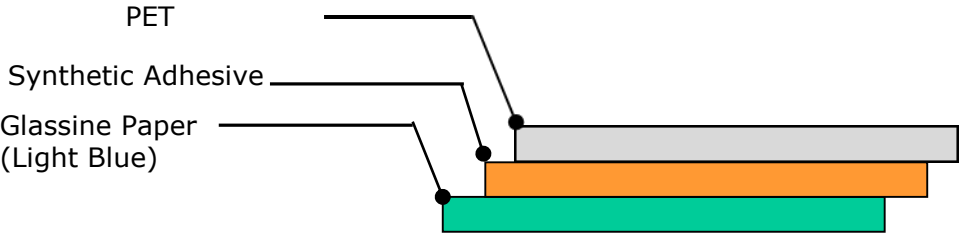

Characteristics

item		Standard	Reference
Material	Backing	PET	
	Base	Synthetic Adhesive	
	Release liner	Paper	Light Blue
Thickness (mm)		90µm ± 6µm	
Width (mm)		1000	
Length (M)		100	
Liner Description		Glassine paper	
Peel adhesion (180 peel, gf/25mm)		Over 2000 (24hr aging)	ASTM D-3330
Temperature Tolerance(°C)	Short term	80	500g,4hr
	Long term	60	500g,10,000 minutes
Halogen Free (F,Cl,Br,I)		Pass	SGS
RoHs (Pb,Hg,Cr,PBBs,PBDEs)		Pass	SGS