

RYA2401

2.4GHz Monopole SMA External Antenna


Datasheet



SPECIFICATION

Item	Min.	Typical	Max.	Unit	Condition
Frequency Range	2380	2470	2470	MHz	
V.S.W.R		≤ 1.8			
Input Impedance		50		ohm	
Antenna Gain			2	dB	
Radiation Efficiency		45		%	
MAX Power			33	dBm	
Operating Temperature	-40		+85	°C	
Dimensions					Length 30mm Diameter 8mm

RETURN LOSS

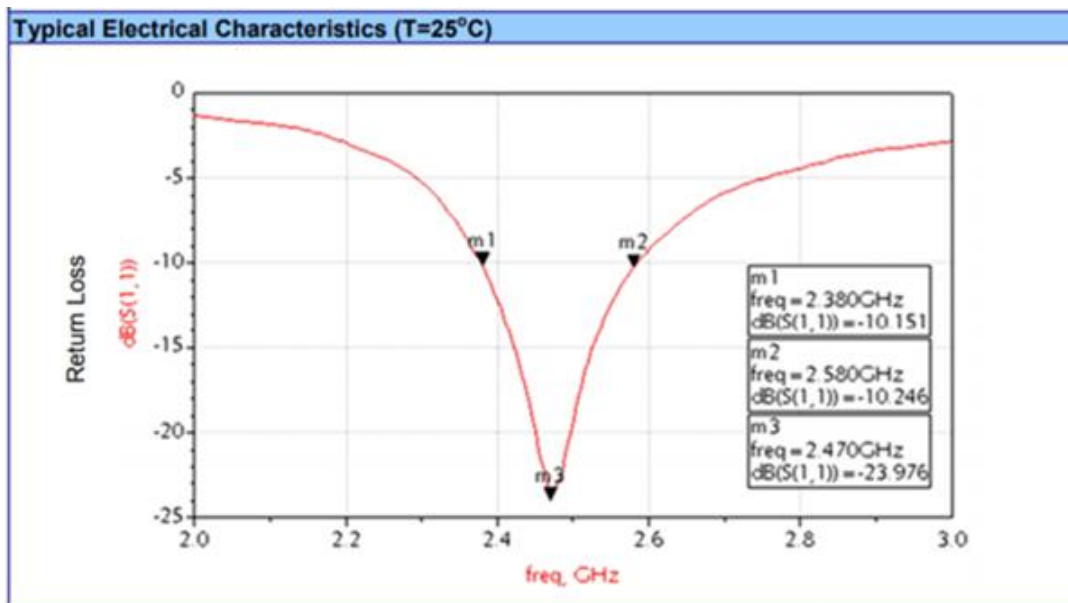

REYAX
TECHNOLOGY CORPORATION, LTD

E-mail: sales@reyax.com

Website: <http://www.reyax.com>