



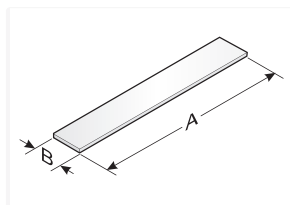

KSO label plate

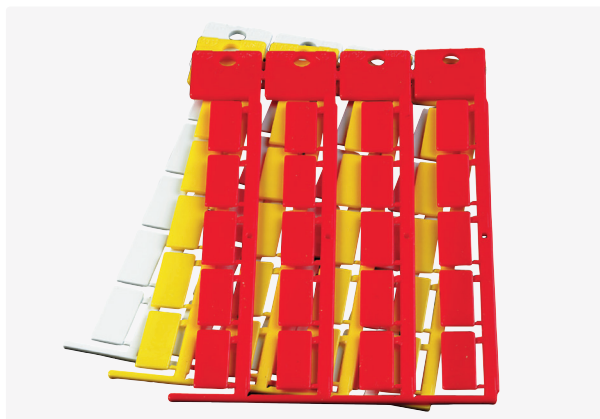

Product information

High-quality, halogen-free, universal label plate for single-line and multi-line inscription.

- Available in different lengths
 - Available in different colors
- Large header labeling area

The KSO label is mounted on cables, cords or conduits with KT series sleeves or the KM, KMH, KMH/Q carriers.
With the 9 mm wide BZS rails, the labels can also be used as device location labeling.

Information, conformities and approvals



Article	Order No.	Color	RAL equiv.	Label size mm (B x A)	Printable area (mm)	Number of characters / lines	Quantity per frame	Software Article	Base plate	PU pcs.
Label length 11 mm										
KSO 11x9	86421024	White	9016	9 x 11	9 x 11	6 / 2	44	60	GP4	1400
KSO 11x9	86421013	Yellow	1018	9 x 11	9 x 11	6 / 2	44	60G	GP4	1400
KSO 11x9	86421015	Red	2012	9 x 11	9 x 11	6 / 2	44	60R	GP4	1400
Label length 15 mm										
KSO 15x9	86421026	White	9016	9 x 15	9 x 15	8 / 2	44	62	GP4	1400
KSO 15x9	86421027	Yellow	1018	9 x 15	9 x 15	8 / 2	44	62G	GP4	1400
KSO 15x9	86421019	Red	2012	9 x 15	9 x 15	8 / 2	44	62R	GP4	1400
Label length 20 mm, long mat design										
KSO 20x9L	86421230	White	9016	9 x 20	9 x 20	11 / 2	20	551	GP4 Single tree adapter 4	640



KSO label plate

Article	Order No.	Color	RAL equiv.	Label size mm (B x A)	Printable area (mm)	Number of characters / lines	Quantity per frame	Software Article	Base plate	PU pcs.
KSO 20x9L	86421232	Yellow	1018	9 x 20	9 x 20	11 / 2	20	552	GP4 Single tree adapter 4	640
KSO 20x9L	86421234	Red	2012	9 x 20	9 x 20	11 / 2	20	553	GP4 Single tree adapter 4	640
Label length 35 mm										
KSO 35x9	86421064	White	9016	9 x 35	9 x 35	19 / 2	12	69W	GP4 Single tree adapter 4	360
KSO 35x9 2x2,5mm	86421068	White	9016	9 x 35	9 x 35	19 / 2	12	303	GP4 Single tree adapter 4	360
KSO 35x9	86421065	Yellow	1018	9 x 35	9 x 35	19 / 2	12	69G	GP4 Single tree adapter 4	360
KSO 35x9	86421066	Red	2012	9 x 35	9 x 35	19 / 2	12	69R	GP4 Single tree adapter 4	360
Label length 70 mm										
KSO 70x9	86421082	White	9016	9 x 70	9 x 70	38 / 2	11	280	GP5 Single tree adapter 5	330
KSO 70x9	86421083	Yellow	1018	9 x 70	9 x 70	38 / 2	11	282	GP5 Single tree adapter 5	330
KSO 70x9	86421084	Red	2012	9 x 70	9 x 70	38 / 2	11	281	GP5 Single tree adapter 5	330

Material properties



Polycarbonate (PC)

Thermal properties



Temperature / temperature range -40 °C – 130 °C



KSO label plate

Fire properties



Fire classification V0

Technical information



Halogen-free

General technical data



Single-line and multi-line labelling

Assembly method



Cable tie system with sleeves

Labelling technology



Plotter



Laser devices



Inkjet