




SMD-version

part no.	12.60547
model	KX – 7T
frequency	38.40 MHz
mode	fundamental
operating temperature	-40° ~ +85°C
frequency tolerance at +25°C	±10 ppm
temperature tolerance at -40° ~ +85°C	±15 ppm
load capacitance C _L	7 pF
series resistance R1 (ESR) max.	50 Ohm
aging at +25°C (first year) max.	±2 ppm
shunt capacitance C ₀ max.	3.0 pF
drive level max.	200 μW
contents of reel	1000 pcs.

Suggested soldering pad:

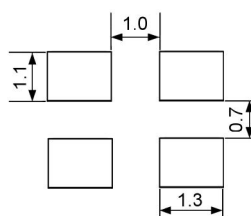

Tape specification:

