

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0022153103
Status: Active
Overview: ffc_fpc_throughhole
Description: 2.54mm (.100") Right Angle, Non-ZIF, Low Profile Receptacle, 10 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-5229-003 \(PDF\)](#)
[Product Specification PS-5229-004 \(PDF\)](#)
[Product Specification PS-5229-005 \(PDF\)](#)
[Product Specification PS-5229-006 \(PDF\)](#)
[Product Specification PS-5229-007 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family FFC/FPC Connectors
Series 5229
Overview ffc_fpc_throughhole
Product Name N/A

Physical

Circuits (Loaded) 10
Contact Position Bottom
Entry Angle 90° Angle
Flammability 94V-0
Mated Height 6.60mm (.260")
Number of Rows 1
Orientation Right Angle
PC Tail Length 3.60mm (.142")
PCB Retention None
Packaging Type Tray
Pitch - Mating Interface 2.54mm (.100")
Pitch - Termination Interface 2.54mm (.100")
Polarized to PCB No
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating -40°C to +105°C
Termination Interface: Style Through Hole
Wire/Cable Type FFC/FPC

Electrical

Current - Maximum per Contact 0.5A, 1A
Voltage - Maximum 200V

Material Info

Old Part Number 5229-10APB

Reference - Drawing Numbers

Product Specification PS-5229-003, PS-5229-004, PS-5229-005,
PS-5229-006, PS-5229-007
Sales Drawing SD-5229-NAPB

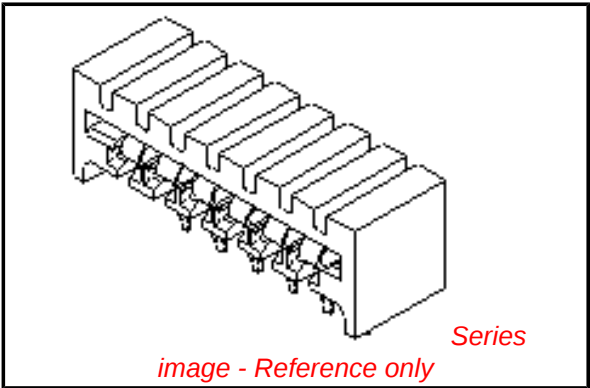


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[5229Series](#)