




ELPRESS®

Product Datasheet

Uninsulated end terminals 0.25 - 50 mm²

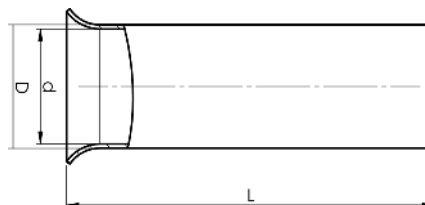

mm ² (Cu)	AWG Cu	Name	d (mm)	D	L	s	Measures acc DIN46228	Material	Pcs/pack	Tool
0,25	24	B0,25-5ET	0,8	1,7	5	5	No	Cu, Cu/Sn	1000	PEB0110T
0,25	24	B0,25-7ET	0,8	1,7	7	7	No	Cu, Cu/Sn	1000	PEB0110T
0,34	22	B0,34-5ET	0,9	1,8	5	5	No	Cu, Cu/Sn	1000	PEB0110T
0,34	22	B0,34-7ET	0,9	1,8	7	7	No	Cu, Cu/Sn	1000	PEB0110T
0,34	22	B0,34-9ET	0,9	1,8	9	9	No	Cu, Cu/Sn	1000	PEB0110T
0,5	20	B0,5-6ET	1	2,1	6	6	Yes	Cu, Cu/Sn	1000	PEB0110T
0,5	20	B0,5-8ET	1	2,1	8	8	No	Cu, Cu/Sn	1000	PEB0110T
0,5	20	B0,5-10ET	1	2,1	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
0,75	18	B0,75-6ET	1,2	2,3	6	6	Yes	Cu, Cu/Sn	1000	PEB0110T
0,75	18	B0,75-8ET	1,2	2,3	8	8	No	Cu, Cu/Sn	1000	PEB0110T
0,75	18	B0,75-10ET	1,2	2,3	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
0,75	18	B0,75-12ET	1,2	2,3	12	12	No	Cu, Cu/Sn	1000	PEB0110T
1	18	B1-6ET	1,4	2,5	6	6	Yes	Cu, Cu/Sn	1000	PEB0110T
1	18	B1-8ET	1,4	2,5	8	8	No	Cu, Cu/Sn	1000	PEB0110T
1	18	B1-10ET	1,4	2,5	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
1	18	B1-12ET	1,4	2,5	12	12	No	Cu, Cu/Sn	1000	PEB0110T
1,5	16	B1,5-7ET	1,7	2,8	7	7	Yes	Cu, Cu/Sn	1000	PEB0110T
1,5	16	B1,5-8ET	1,7	2,8	8	8	Yes	Cu, Cu/Sn	1000	PEB0110T
1,5	16	B1,5-10ET	1,7	2,8	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
1,5	16	B1,5-12ET	1,7	2,8	12	12	Yes	Cu, Cu/Sn	1000	PEB0110T
1,5	16	B1,5-15ET	1,7	2,8	15	15	No	Cu, Cu/Sn	1000	PEB0110T18
1,5	16	B1,5-18ET	1,7	2,8	18	18	Yes	Cu, Cu/Sn	1000	PEB0110T18
1,5	16	B1,5-20ET	1,7	2,8	20	20	No	Cu, Cu/Sn	1000	PEB0110T18
2,5	14	B2,5-7ET	2,2	3,4	7	7	Yes	Cu, Cu/Sn	1000	PEB0110T
2,5	14	B2,5-8ET	2,2	3,4	8	8	Yes	Cu, Cu/Sn	1000	PEB0110T
2,5	14	B2,5-10ET	2,2	3,4	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
2,5	14	B2,5-12ET	2,2	3,4	12	12	Yes	Cu, Cu/Sn	1000	PEB0110T
2,5	14	B2,5-15ET	2,2	3,4	15	15	No	Cu, Cu/Sn	1000	PEB0110T18
2,5	14	B2,5-18ET	2,2	3,4	18	18	Yes	Cu, Cu/Sn	1000	PEB0110T18
2,5	14	B2,5-20ET	2,2	3,4	20	20	No	Cu, Cu/Sn	1000	PEB0110T18
4	12	B4-9ET	2,8	4	9	9	Yes	Cu, Cu/Sn	1000	PEB0110T
4	12	B4-10ET	2,8	4	10	10	Yes	Cu, Cu/Sn	1000	PEB0110T
4	12	B4-12ET	2,8	4	12	12	Yes	Cu, Cu/Sn	1000	PEB0110T
4	12	B4-18ET	2,8	4	18	18	Yes	Cu, Cu/Sn	1000	PEB0110T18
4	12	B4-20ET	2,8	4	20	20	No	Cu, Cu/Sn	1000	PEB0110T18
6	10	B6-10ET	3,5	4,7	10	10	Yes	Cu, Cu/Sn	250	PEB0110T
6	10	B6-12ET	3,5	4,7	12	12	Yes	Cu, Cu/Sn	250	PEB0110T
6	10	B6-15ET	3,5	4,7	15	15	Yes	Cu, Cu/Sn	250	PEB0110T18
6	10	B6-18ET	3,5	4,7	18	18	Yes	Cu, Cu/Sn	250	PEB0110T18
6	10	B6-20ET	3,5	4,7	20	20	No	Cu, Cu/Sn	250	PEB0110T18
6	10	B6-25ET	3,5	4,7	25	25	No	Cu, Cu/Sn	250	PEB0110T18
10	8	B10-12ET	4,5	4,7	12	12	Yes	Cu, Cu/Sn	250	GEB1025
10	8	B10-15ET	4,5	4,7	15	15	Yes	Cu, Cu/Sn	250	GEB1025
10	8	B10-18ET	4,5	4,7	18	18	Yes	Cu, Cu/Sn	250	GEB1025
10	8	B10-20ET	4,5	4,7	20	20	No	Cu, Cu/Sn	250	GEB1025
10	8	B10-25ET	4,5	4,7	25	25	No	Cu, Cu/Sn	250	GEB1025
16	6	B16-12ET	5,8	7,5	12	12	Yes	Cu, Cu/Sn	250	GEB1025
16	6	B16-15ET	5,8	7,5	15	15	Yes	Cu, Cu/Sn	250	GEB1025
16	6	B16-18ET	5,8	7,5	18	18	Yes	Cu, Cu/Sn	250	GEB1025
16	6	B16-20ET	5,8	7,5	20	20	No	Cu, Cu/Sn	250	GEB1025
16	6	B16-25ET	5,8	7,5	25	25	Yes	Cu, Cu/Sn	250	GEB1025
16	6	B16-32ET	5,8	7,5	32	32	Yes	Cu, Cu/Sn	250	GEB1025
25	4	B25-12ET	7,3	9,5	12	12	No	Cu, Cu/Sn	250	GEB1025
25	4	B25-15ET	7,3	9,5	15	15	Yes	Cu, Cu/Sn	250	GEB1025
25	4	B25-18ET	7,3	9,5	18	18	Yes	Cu, Cu/Sn	250	GEB1025
25	4	B25-25ET	7,3	9,5	25	25	Yes	Cu, Cu/Sn	100	GEB1025
25	4	B25-32ET	7,3	9,5	32	32	Yes	Cu, Cu/Sn	100	GEB1025
35	2	B35-18ET	8,3	11	18	18	Yes	Cu, Cu/Sn	100	GEB3550
35	2	B35-20ET	8,3	11	20	20	No	Cu, Cu/Sn	100	GEB3550
35	2	B35-25ET	8,3	11	25	25	Yes	Cu, Cu/Sn	100	GEB3550
35	2	B35-32ET	8,3	11	32	32	Yes	Cu, Cu/Sn	100	GEB3550
50	1/0	B50-18ET	10,3	13	18	18	Yes	Cu, Cu/Sn	100	GEB3550
50	1/0	B50-22ET	10,3	13	22	22	No	Cu, Cu/Sn	100	GEB3550
50	1/0	B50-25ET	10,3	13	25	25	Yes	Cu, Cu/Sn	100	GEB3550
50	1/0	B50-32ET	10,3	13	32	32	Yes	Cu, Cu/Sn	100	GEB3550

t = palm thickness

We can also offer areas over 50 mm².



ELPRESS®