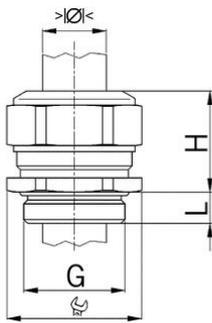


Cable glands Progress® nickel-plated brass for high temperature application

**Short entry thread metric****Type approval: Progress MS HT**

- Two-piece sealing insert
- not overall length insulated

Order number:	1000.17.92
E-No:	121069448
EAN:	7611614164748
Material	Nickel-plated brass
Seal	FPM
O-ring	FPM
Operation temperature	-40°C / +200°C
Strain relief	Version A acc. to EN 62444
Protection class	IP 68 (up to 10 bar) / IP 69
Entry thread	M16x1.5
Clamping range with insert min.	6.0 mm
Clamping range with insert max.	8.0 mm
Clamping range without insert min.	8.0 mm
Clamping range without insert max.	10.5 mm
Wrench size	18 mm
Dimension H	22 mm
Thread length L	5 mm
Dispatch	50