


Cable glands Progress® nickel-plated brass

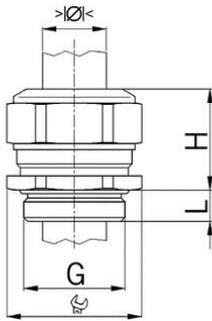

Short entry thread metric

Type approval: Progress MS

- Two-piece sealing insert
- not overall length insulated

| | |
|------------------------------------|------------------------------|
| Order number: | 1000.25 |
| E-No: | 121069608 |
| EAN: | 7611614104577 |
| Material | Nickel-plated brass |
| Seal | TPE |
| O-ring | NBR |
| Operation temperature | -40°C / +100°C |
| Strain relief | Version A acc. to EN 62444 |
| Protection class | IP 68 (up to 10 bar) / IP 69 |
| NEMA Type rating | 4X |
| Entry thread | M25x1.5 |
| Clamping range with insert min. | 12.5 mm |
| Clamping range with insert max. | 16.0 mm |
| Clamping range without insert min. | 16.0 mm |
| Clamping range without insert max. | 20.5 mm |
| Wrench size | 30 mm |
| Dimension H | 28 mm |
| Thread length L | 7 mm |
| UL - clamping range | 14.5-16.0 mm |
| Dispatch | 25 |

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.