


Cable glands Progress® nickel-plated brass

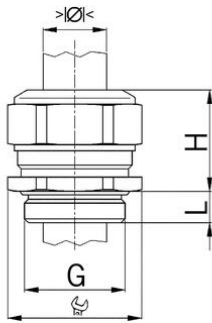

Short entry thread Pg

Type approval: Progress MS

- One-piece sealing insert
- not overall length insulated

Order number:	1000.29.230
E-No:	121075618
EAN:	7611614105857
Material	Nickel-plated brass
Seal	TPE
O-ring	NBR
Operation temperature	-40°C / +100°C
Protection class	IP 68 (up to 10 bar) / IP 69
NEMA Type rating	4X
Entry thread	Pg 29
Clamping range min.	19.0 mm
Clamping range max.	23.0 mm
Wrench size	38 mm
Dimension H	28 mm
Thread length L	8.0 mm
UL - clamping range	21.0-23.0 mm
Dispatch	25

Available with sealing inserts conformity with EN 45545 / NFPA 130. When placing an inquiry, prefix the article number by the capital F.