


Metal protection conduit for Ex Applications

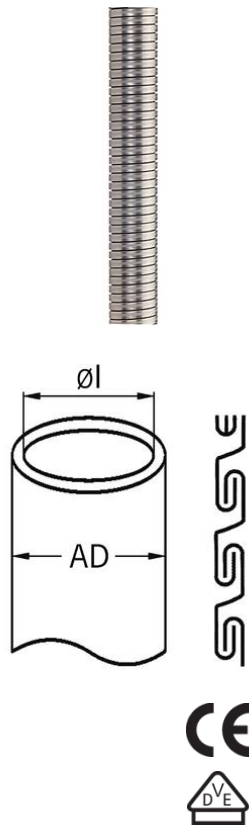

Protective metal conduit non liquid-tight

- Protective metal conduit non liquid-tight
- FLEXAgraff®-AS

Order number:	1080.101.014
E-No:	125451299
EAN:	7611614113517
Material	Steel galvanized, double-overlapped
Properties	High tensile, torsional- and bending strength, highly flexible, no untwisting of the conduit
Application	Machine and plant constructions, vehicle construction, shipbuilding, automation, electrical installations
Tested acc. to	EN / IEC 61386-23
Protection class	IP 40
Operation temperature	-50°C / +250°C
Outer diameter	17 mm
Inner diameter	14 mm
Bending radius static	60 mm
Bending radius dynamic	150 mm
Bushing	5031.027.011
Dispatch	50

Available on request:

- Stainless steel A2