


Cable glands Progress® EMC Rapid nickel-plated brass with contact disc

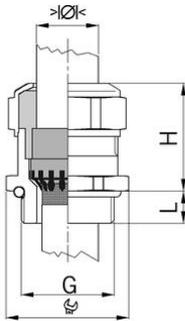

Short entry thread metric

Type approval: Progress MS EMV Rapid

- One-piece sealing insert
- not overall length insulated

| | |
|------------------------------------|---|
| Order number: | 1081.25.190 |
| E-No: | 121072538 |
| EAN: | 7611614207070 |
| Material | Nickel-plated brass |
| Contact sleeve | Nickel-plated brass |
| Contact disc | Stainless steel A2 |
| Seal | TPE |
| O-ring | NBR |
| Operation temperature | -40°C / +100°C |
| Strain relief | Version A acc. to EN 62444 |
| Protection class | IP 68 (up to 10 bar) / IP 69 |
| NEMA Type rating | 4X |
| Properties | For a quick installation of partially dismantled cables as well as thoroughly shielded cables |
| Entry thread | M25x1.5 |
| Clamping range without insert min. | 16.0 mm |
| Clamping range without insert max. | 19.0 mm |
| Wrench size | 30 mm |
| Dimension H | 33 mm |
| Thread length L | 7 mm |
| Dispatch | 25 |

